

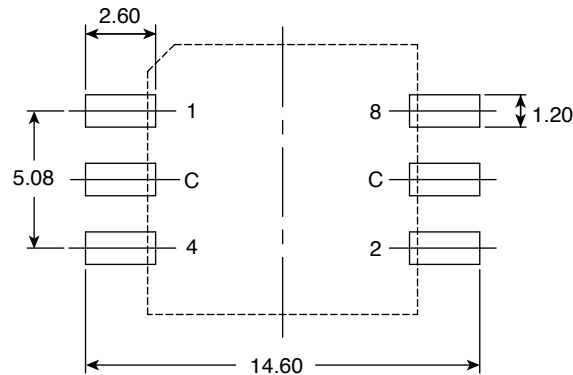
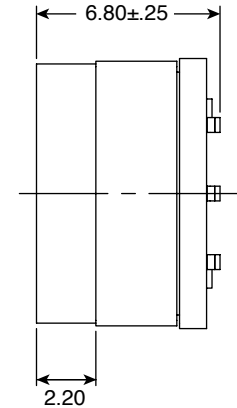
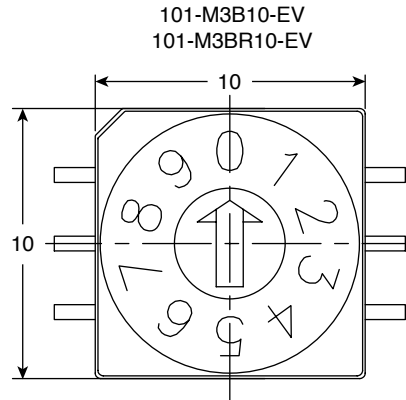


**DIMENSIONS: mm**

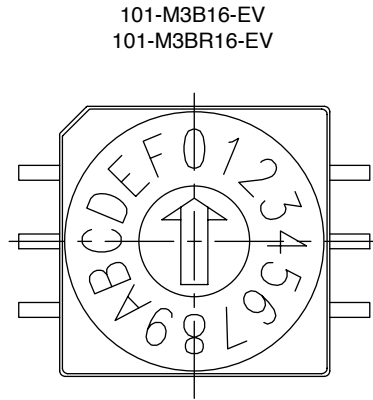

P.C.B. LAYOUT

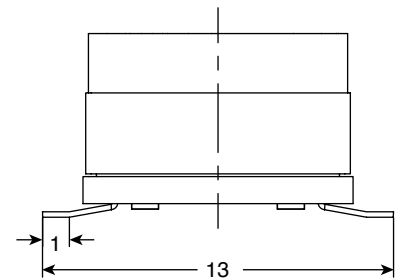

Type	Circuit Characteristics																
10 STEP	Code	Position x ON															
		0	1	2	3	4	5	6	7	8	9	A	B	C	D	E	F
	1	x		x		x		x		x							
	2			x	x			x	x								
	4					x	x	x	x								
	8									x	x						

Type	Circuit Characteristics																
16 STEP	Code	Position x ON															
		0	1	2	3	4	5	6	7	8	9	A	B	C	D	E	F
	1	x		x		x		x		x		x		x		x	
	2			x	x			x	x			x	x			x	x
	4					x	x	x	x					x	x	x	x
	8									x	x	x	x	x	x	x	x

**Electrical Specifications:**

- Rating: Non-Switching Rating 400mA/24VDC  
Switching Rating 150mA/24VDC
- Initial Contact Resistance: 100m Ω Max.
- Dielectric Strength: 250VAC Min.
- Insulation Resistance: 100MΩ Min. (250VDC Megger)

Mouser Stock No.	Packaging
101-M3B10-EV	Tube
101-M3B16-EV	Tube
101-M3BR10-EV	Reel
101-M3BR16-EV	Reel

**Mechanical Specifications:**

- Operating Force: 400gf cm Max.
- Operating Temperature: -60°C to 125°C

**Note:**

- RoHS Compliant

**Coded Rotary Switches**

101-M3B10-EV, 101-M3B16-EV, 101-M3BR10-EV,  
101-M3BR16-EV



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Mountain Switch:

[101-M3BR16-EV](#) [101-M3B10-EV](#) [101-M3BR10-EV](#) [101-M3B16-EV](#)