


DIMENSIONS: mm

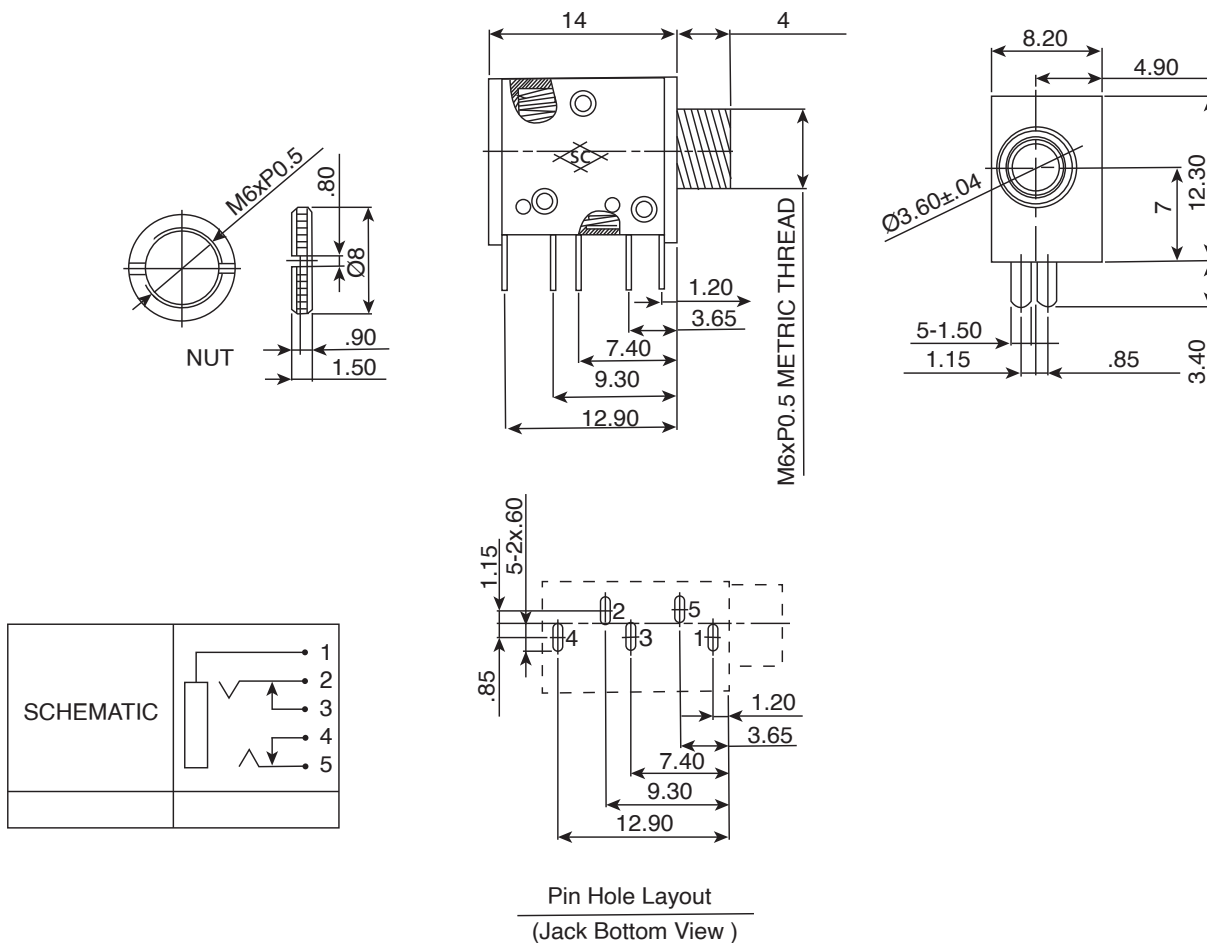

SPECIFICATIONS:

- Contact Resistance: 30mΩ max
- Current Rating: Max 5A/24VDC
- Insulation Resistance: 100MΩ min. at 500VDC
- Dielectric Withstand Voltage: 500VAC for one minute.

Note:

- RoHS Compliant by Exemption

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[161-368M1-EX](#)