
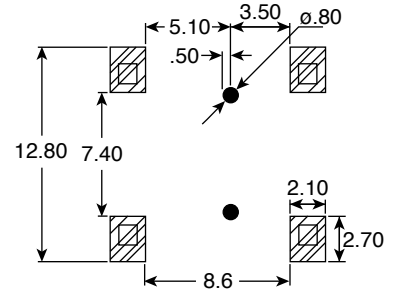
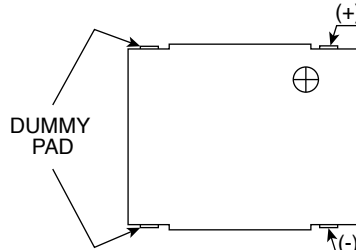


Dimensions: mm

Part Number:



254-EMB1405-RO

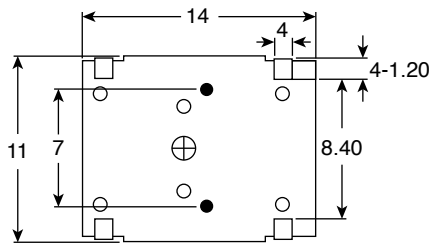


RECOMMENDED PCB LAYOUT

Frequency Response Curve

X: 2.7384kHz Y: 91.73dB ZA: Live Curve SSR T. RMS
A: Frequency Response, Magn dB re 20.00 µPA

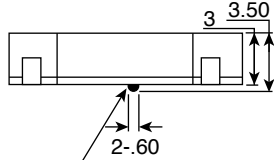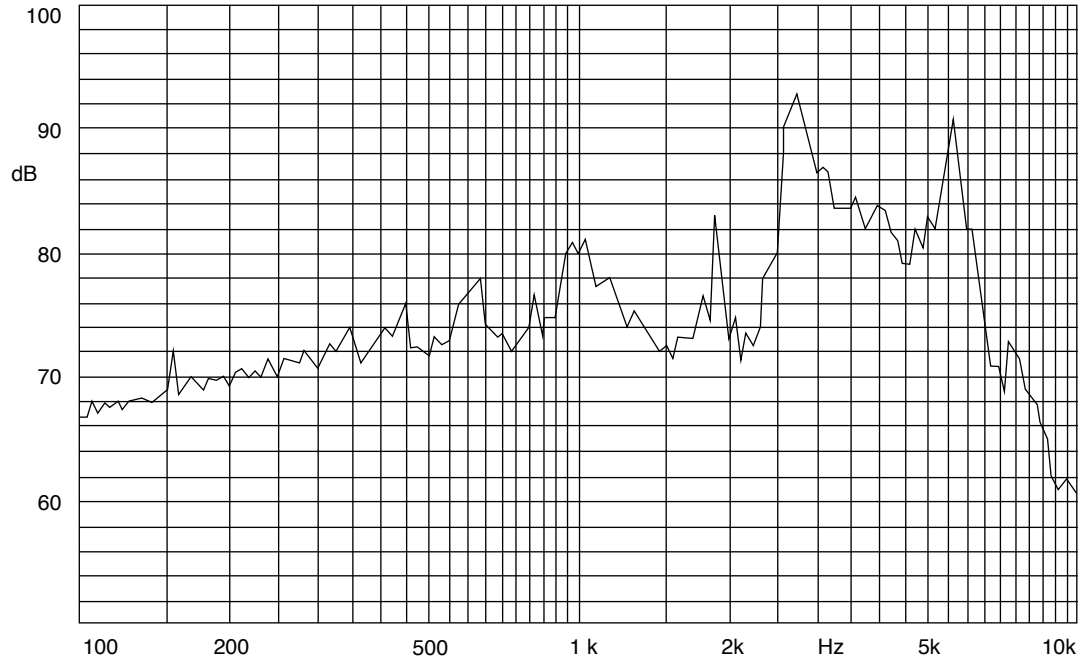

LOCATED FUNCTION

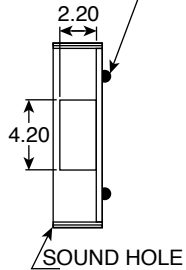

Magnetic Buzzer

Electrical Specifications:

- Rated Voltage: 5.0 Vo-p
- Operating Voltage: 3.0 to 6.0 Vo-p
- Consumption Current:
Mean: 80mA (Max.)
Peak: 240mA (Max.)
- Sound Pressure Level: 87 dBA (Min.)
- Rated Frequency: 2730Hz
- Direct Current Resistance: 43Ω±3

Mechanical Specifications:

- Operating Temperature: -30°C to 70°C
- Storage Temperature: -40°C to 85°C

Soldering Specifications:

- Hand Soldering: 360±10°C, 2±.50 Sec.
Recommend using constant searing-iron
- Soldering into solder bath: 260±5°C, 5 to 10 Sec.

Note:

- RoHS Compliant
- Not Washable

KT-400447

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobitone:](#)

[254-EMB1405-RO](#)