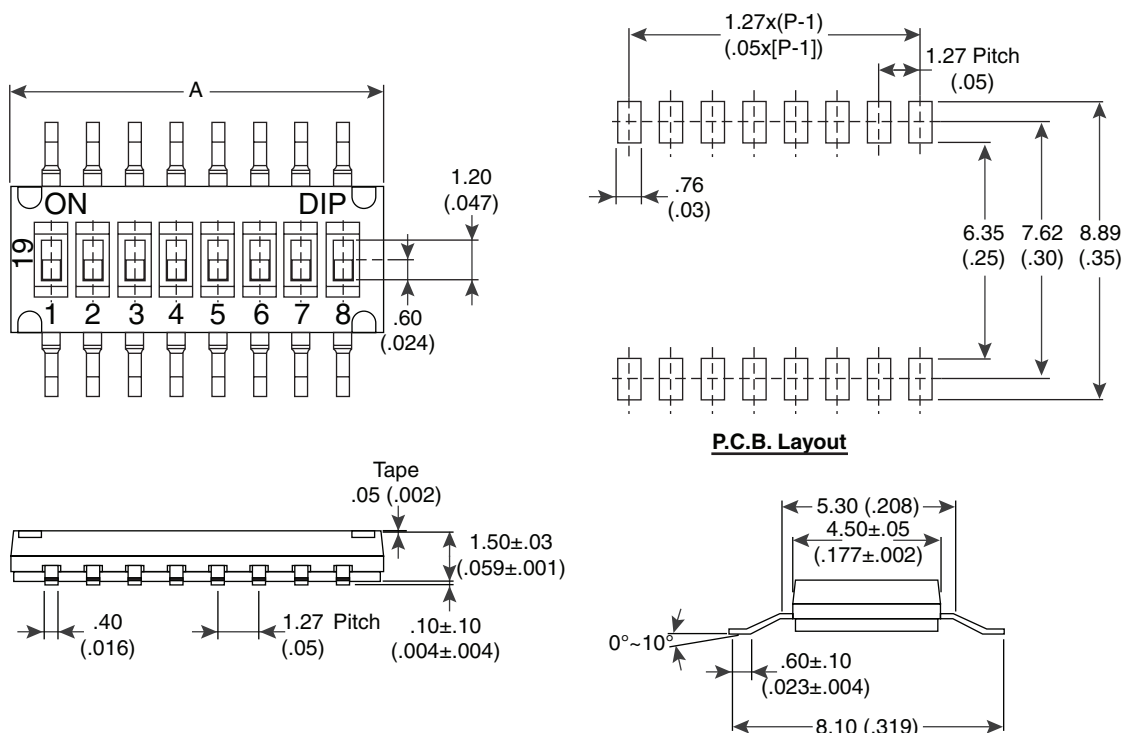
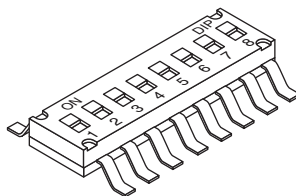


Dimensions: mm (in.)

**Electrical Specifications:**

- Rating: Non-switching: 100mA/50V DC
Switching: 25mA/24V DC
- Contact resistance: 100mΩ max. (initial)
- Insulation resistance: 100MΩ min.

Mechanical Specifications:

- Operating temperature: -40°C ~ +85°C
- Operation force: 500gf max.

Note:

- RoHS Compliant

Mouser Stock No.	No. of Pos.	Dim A. mm (In.)	Top Tape
106-DHNF2-EV	2	3.77 (.148)	Without
106-DHNF4-EV	4	6.31 (.248)	Without
106-DHNF6-EV	6	8.85 (.348)	Without
106-DHNF8-EV	8	11.39 (.448)	Without
106-FHD10-EV	10	13.93 (.548)	Without
106-FHD2T-EV	2	3.77 (.148)	With
106-FHD4T-EV	4	6.31 (.248)	With

Dip Switches

106-DHNF2-EV, 106-DHNF4-EV, 106-DHNF6-EV, 106-DHNF8-EV,
106-FHD10-EV, 106-FHD2T-EV, 106-FHD4T-EV

**Mountain
Switch**

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[106-FHD2T-EV](#) [106-FHD4T-EV](#) [106-FHD10-EV](#) [106-DHNF6-EV](#) [106-DHNF4-EV](#) [106-DHNF2-EV](#) [106-DHNF8-EV](#)