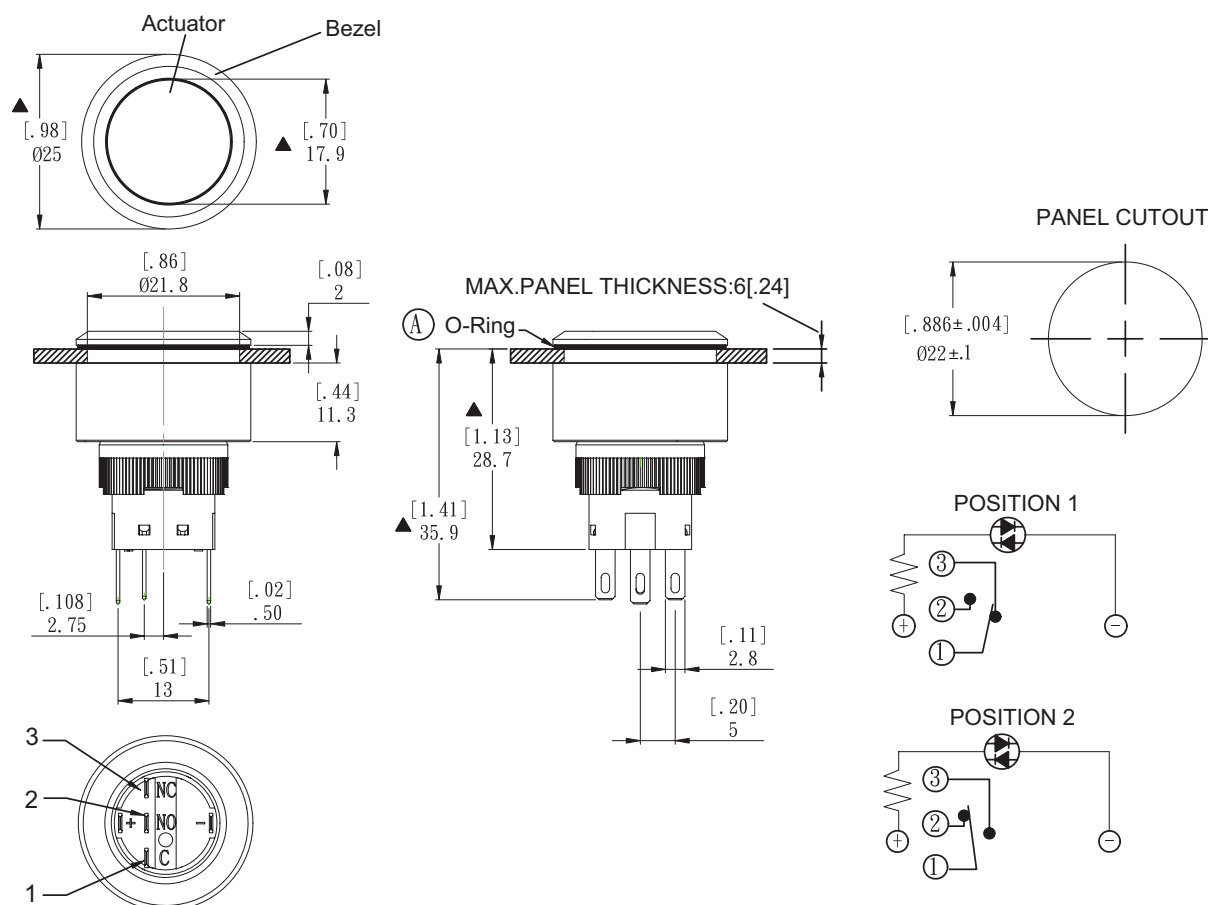


Dimensions: mm (In.)

**Electrical Specifications:**

- Rating: Resistive load 3A/250VAC.
- Life: 50,000 make-and-break cycles at full load.
- Insulation Resistance: 1,000MΩ Min. at 500VDC
- Dielectric Strength: 2,000 V RMS@ sea level.
- Contact Resistance: 50mΩ Max. @1A 12VDC(initial value).

Mechanical Specifications:

- Life: Momentary 1,000,000
- Operating Temperature: -20°C to 55°C

Note:

- Actuator Type: Transparent Blue Actuator LED in Blue only.
- LED Color: Blue
- RoHS Compliant

Illuminated Pushbutton Switch
107-KP87-F7-EV

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

107-KP87-F7-EV