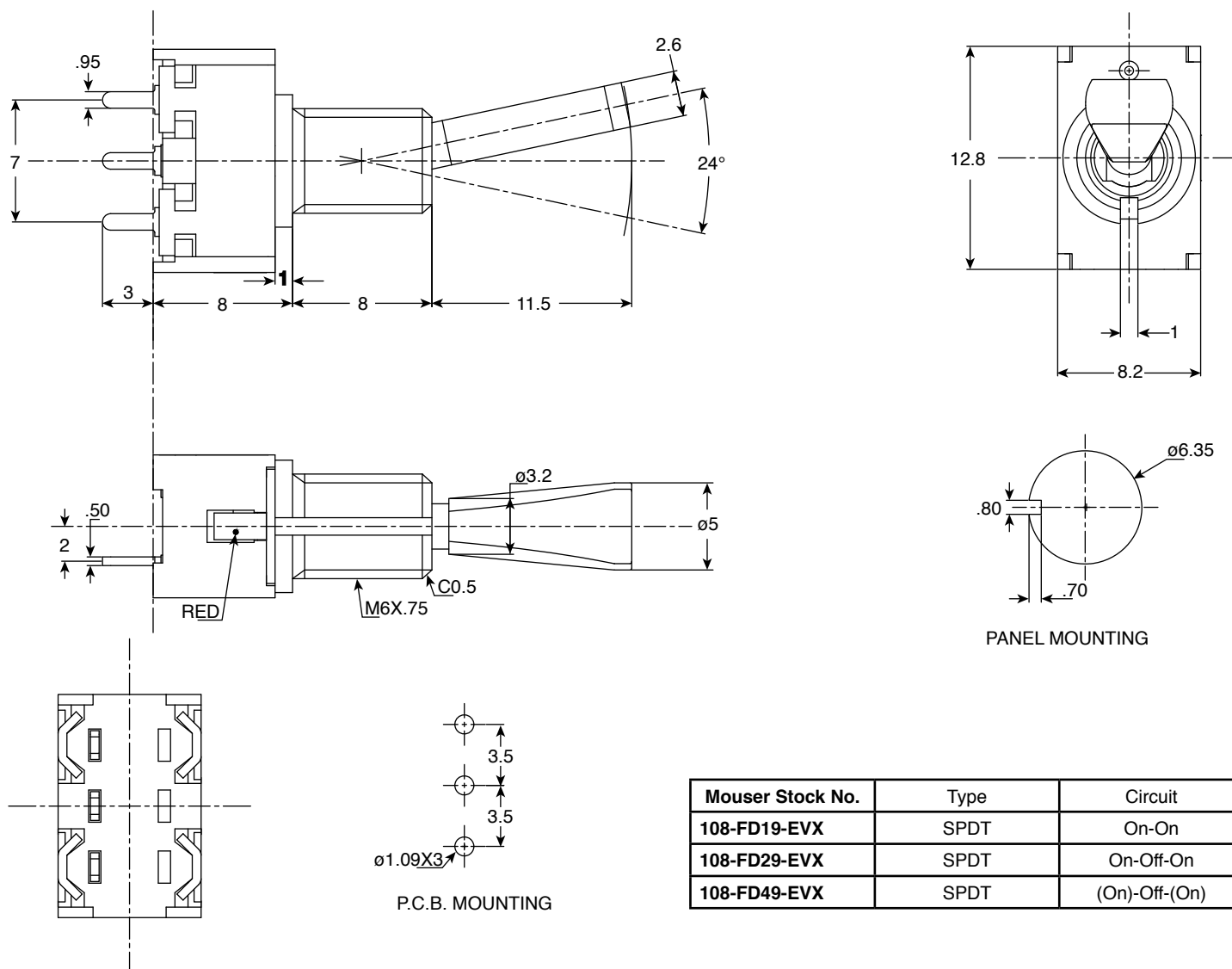


## DIMENSIONS: mm

**Electrical Specifications:**

- Contact Resistance: 30mΩ Max. initial @ 2-4VDC 100mA
- Rating: 0.1A/30VDC
- Insulation Resistance: 100MΩ Min. @ 0.5mA/500V
- Dielectric Strength: 1,000V RMS @ sea level

**Mechanical Specifications:**

- Life: 10,000 make-and-break cycles
- Operating Temperature: -30°C to 85°C

**Note:**

- RoHS Compliant by Exemption

**Toggle Switches**

108-FD19-EVX, 108-FD29-EVX, 108-FD49-EVX

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[108-FD29-EVX](#) [108-FD49-EVX](#) [108-FD19-EVX](#)