




KXACC-082

Male 10-Pin Split Ribbon Cable

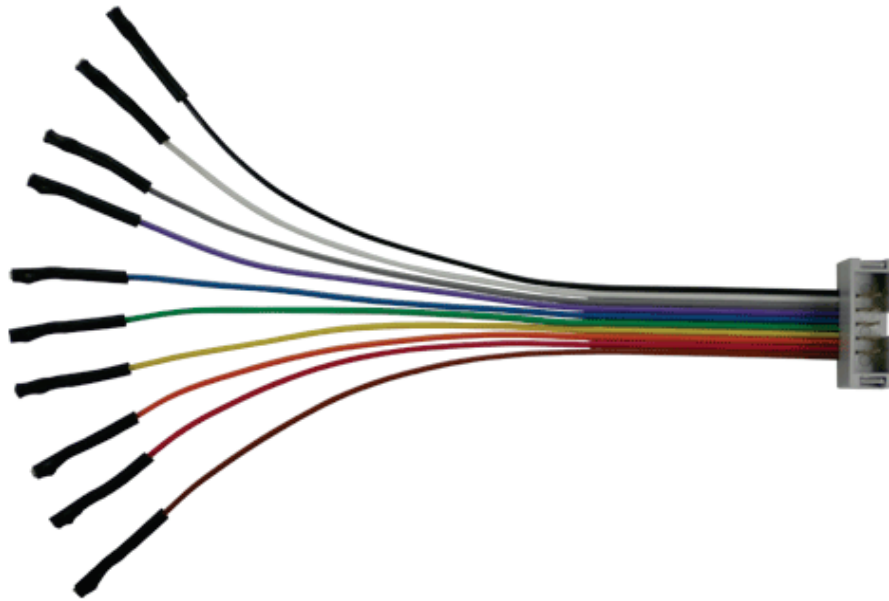

1. SPECIFICATIONS

PARAMETER	VALUE
Number of Conductors	10
Cable Type	Flat Cable, Unshielded
Wire Gage	28 AWG
Cable Length	6.0" (Inches)
Color	Multiple (Resistor Color Code)
Connectors	Each Strand: 0.026" I.D. Pin Socket. Male Plug: 5X2 IDC, 0.10" [2.54mm] pitch, shrouded, with 0.17" wide center polarizing notch.
Compatibility	KX1400 Audio Playback IC Development Kit USB-910H Embedded Systems Interface
Mating Connectors	3M Company P/N: 3473-7600 Assmann Electronics P/N: AWP10-7241-T-R Assmann Electronics P/N: AWP10-8241-T-R Sullins Connector Solutions P/N: SFH11-PxxC-D05-RA-xx Sullins Connector Solutions P/N: SFH11-PxxC-D05-ST-xx

KXACC-082: Male 10-Pin Split Ribbon Cable

Ordering Part Number	Package/Case	Operating Temp.	Packaging
KXACC-082	N/A	N/A	Bulk

Contact Information

Keterex, Inc.

7320 N. Mo Pac Expressway

Suite 201

Austin, Texas 78731

Tel: 512-346-8800

www.keterex.com

Email: support@keterex.com

Information furnished by Keterex, Inc. in this document is believed to be accurate and reliable. However, no responsibility is assumed for its use. Information in this document is subject to change without notice.

Trademarks: The Keterex name and logo are registered trademarks of Keterex Incorporated. Other products or brand names mentioned herein are trademarks or registered trademarks of their respective holders.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Keterex:](#)

[KXACC-082](#)