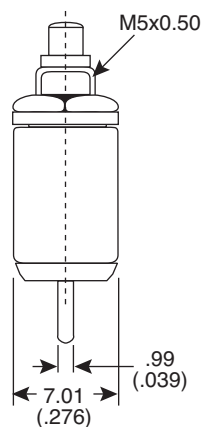
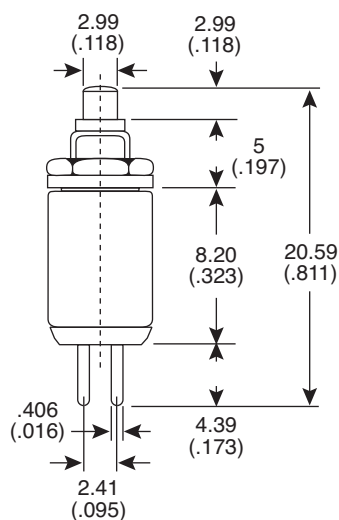
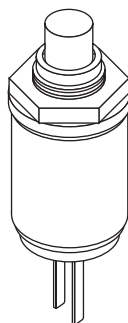


Dimensions: mm (in.)

**Electrical Specifications:**

- Rating: 0.5A/125VAC
- Contact Resistance: 20mΩ @ 2.5VDC and 1A or less
- Insulation Resistance: 100MΩ @ 500VDC for more
- Dielectric Strength: 1,000VAC for 1 minute

Mechanical Specifications:

- Circuit: SPST Off-(On)
- Operating Temperature: -10°C to +55°C

Materials:

- Terminal: Gold plated sterling silver plate
- Spring Washer: Nickel plated steel/ copper plate
- Hex Nut: Nickel plated nickel sheet
- Shaft: ABS
- Body: Phenolresin, Black
- Button: 10PA018 (red); 10PA019 (black)

Soldering Process:

- Temperature: 270°C within 3 sec.
- Note: Recommended for hand soldering only

Pushbutton Switches
10PA018, 10PA019

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

10PA018 10PA019