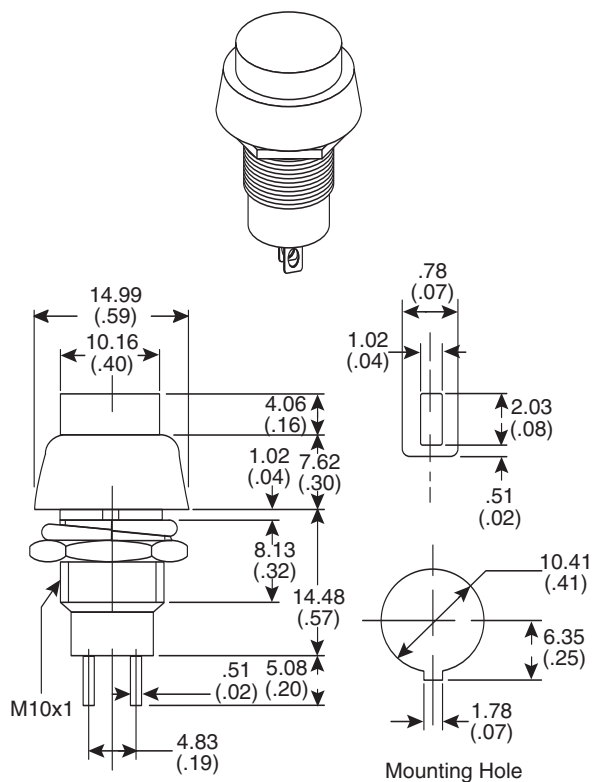


Dimensions: mm (In.)

**Electrical Specifications:**

- Rating: 3A / 125VAC or 1A / 250VAC
- Insulation resistance: 100M Ω (min) @ 500VDC
- Dielectric strength: 1500VAC for 1 minute
- Contact resistance: 20m Ω (max) @ 1A 2.5VDC

Mouser Stock No.	Button Color	Frame Color	Button Type
10PA322	Red	Black	Round
10PA323	Black	Black	Round

Mechanical Specifications:

- Circuit: SPST off-(on)

Pushbutton Switches
10PA322, 10PA323

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[10PA323](#) [10PA322](#)