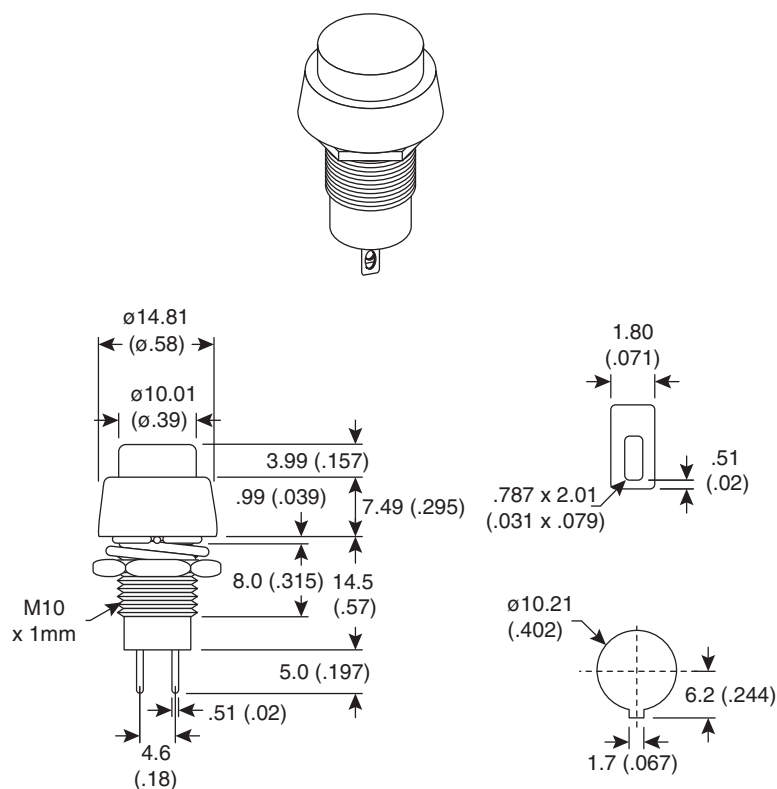


Dimensions: mm (In.)

**Mechanical Specifications:**

- Circuit: 2P SPST, Off - On
- Mechanical life: 100,000 operations

Electrical Specifications:

- Contact resistance: 20m Ω max. @ 2.5VDC 1A
- Insulation resistance: 100M Ω min. @ 500VDC
- Dielectric Strength: 1500VAC for 1 minute
- Rating: 3A / 125VAC 1A / 250VAC
- Electrical life: 50,000 operation

Materials:

- Contacts: Silver plated silver clad copper
- Button Color: red (10PP422), black (10PP423)

Pushbutton Switches
10PP422, 10PP423

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[10PP422](#) [10PP423](#)