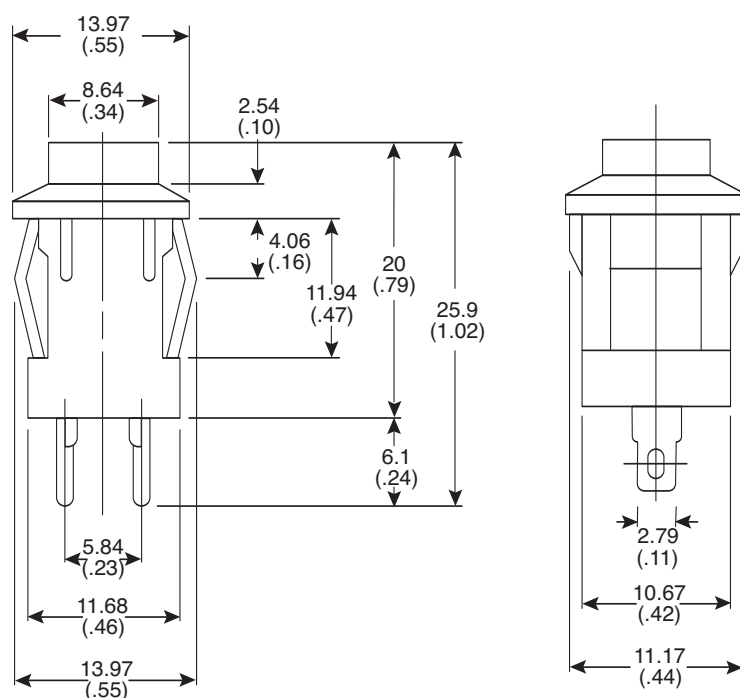
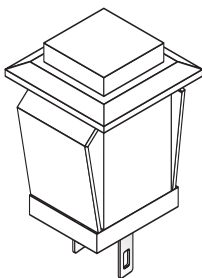


Dimensions: mm (In.)

**Electrical Specifications:**

- Rating: 1A/125VAC, 5A/250VAC
- Contact resistance: 20mΩ max. @ 1A, 2.5VDC
- Insulation resistance: 100MΩ min. @ 500VDC
- Dielectric Strength: 1500VAC for 1 minute

Mechanical Specifications:

- Mechanical-30,000 cycles
- Mounting hole: .49 x .44 inches

Mouser Stock No.	Type	Circuit	Button Color
10PA210	SPST	Off - (On)	Red
10PA211	SPST	Off - (On)	Black

Pushbutton Switches
10PA210, 10PA211

**Mountain
Switch**

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

10PA211 10PA210