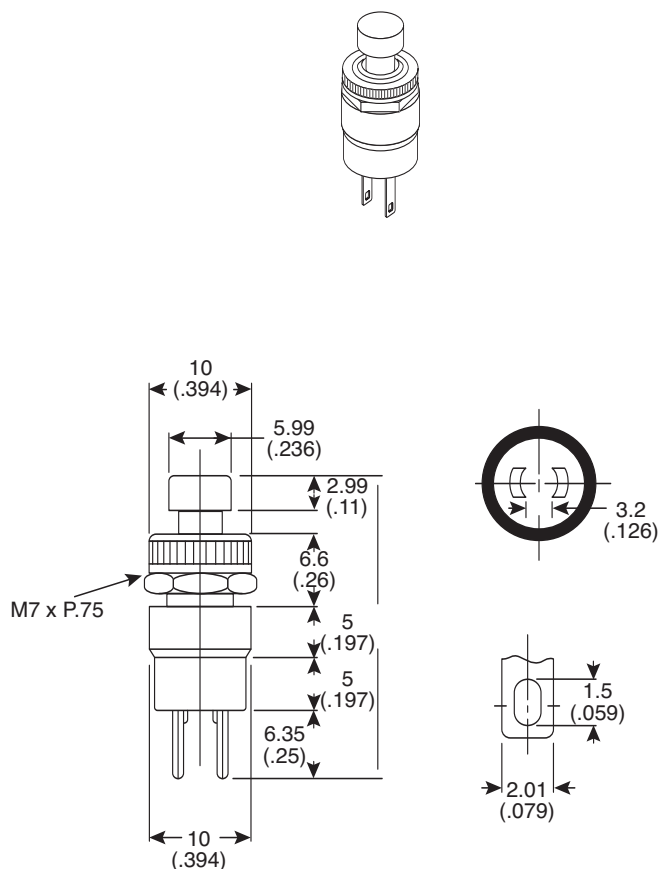


Dimensions: mm (In.)

**Electrical Specifications:**

- Rating: 1A/125VAC
- Insulation resistance: 100M Ω (min.) @ 500VDC
- Dielectric Strength: 1000VAC for 1 minute
- Contact resistance: 20m Ω (max.)

Mouser Stock No.	Type	Circuit	Button Color
10PA220	SPST	Off-(On)	Red
10PA221	SPST	Off-(On)	Black

Pushbutton Switches
10PA220, 10PA221

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[10PA221](#) [10PA220](#)