




D-SUBMINIATURE CONNECTORS: K42X Series Dual-Port D-Sub Combo

K42X-B25P/E9P-A4N Dimensions Dimensions in mm

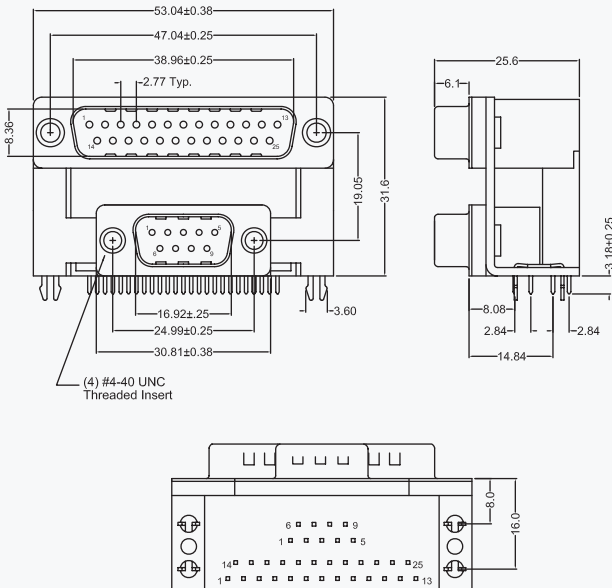

2D Drawing

IGES

STEP

3D PDF

Solder Profile

CofC RoHS Compliant

CofC REACH Compliant

UL Plastic File

Certificate of Origin

Check Stock

Request a Sample

Send Us An Email

Generated Part Number

Part Number Builder

	-					
Series		Top Shell Size	Bottom Shell Size	Center Distance	Boardlock Option	Jackscrews Option

Series

K42X - Dual-Port D-Subminiature Connector

Top/Bottom Shell Size

25/9 - 25 Contacts over 9 Contacts

Top/Bottom Connector Type

S/P - Receptacle/Plug

S/S - Receptacle/Receptacle

Center to Center Distance

A - 0.750" (Standard)

Boardlocks Option

4N - Boardlocks (Standard)

Jackscrews Option

Blank - No Jackscrews

J - #4-40 Jackscrews Installed

Contact Kycon for Other Options

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kycon:](#)

[K42X-B25S/E9P-A4N](#) [K42X-B25S/E9PA4N30](#) [K42X-B25P/E9S-A4N](#) [K42X-B25S/E9S-A4N](#) [K42X-B25P/E9P-A4N](#)
[K42X-B25P/E9P-A4NJ](#) [K42X-B25P/E9S-A4NJ](#) [K42X-B25S/E9P-A4NJ](#) [K42X-B25S/E9S-A4NJ](#)