


D-SUBMINIATURE CONNECTORS:
K66XHT Series
 High Temperature Right Angle PCB Mount

K66XHT Series Dimensions
 Dimensions in mm

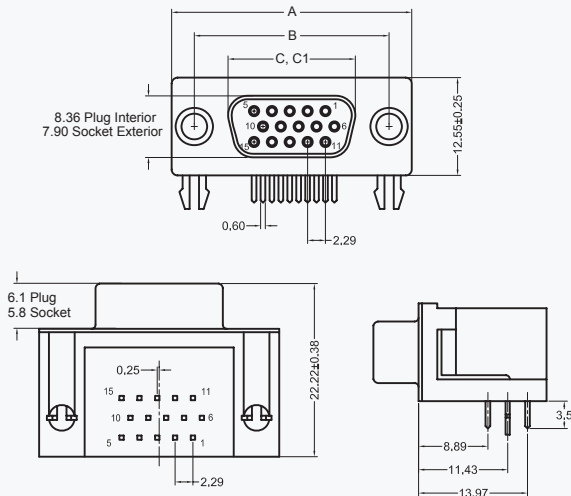

Shell Size	Dimensions (mm)					
	A	B	C	C1	D	E
15 (E)	1.213 ±.015 ±0.38	.984 ±.005 ±0.13	.643 ±.010 ±.025	.666 ±.010 ±0.25	.090 ±.005 ±0.13	.010 ±.005 ±0.13
26 (A)	1.541 39.14	1.312 33.32	.971 24.66	.994 25.25	.090 2.29	.020 0.51
44 (B)	2.088 53.04	1.852 47.04	1.511 38.38	1.534 38.96	.090 2.29	.020 0.51
62 (C)	2.729 69.32	2.500 63.50	2.159 54.84	2.182 55.42	.095 2.41	.023 0.58

C = Exterior of Female Shell (S)
 C1 = Interior of Male Shell (P)

2D Drawing	IGES	STEP	3D PDF
Solder Profile	CofC RoHS Compliant	CofC REACH Compliant	UL Plastic File
Certificate of Origin	Check Stock	Request a Sample	Send Us An Email

Generated Part Number

Part Number Builder

Series - Shell Size Contact - Contact Type - Mounting Option

Series

K66XHT - Reflow Compatible Version

Shell Size-Contact Option

- E - 15 Contacts
- A - 26 Contacts
- B - 44 Contacts

Contact Type

- P - Pin Contact (Plug)
- S - Socket Contact (Receptacle)

Mounting Option

- N - With Boardlocks and #4-40 UNC Threaded Inserts
- NJ - With Boardlocks and #4-40 Jackscrews Installed

Contact Kycon for VESA and Other Options

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Kycon:

[K66XHT-E15P-N](#) [K66XHT-E15P-NJ](#) [K66XHT-A26S-N30](#) [K66XHT-A26P-N](#) [K66XHT-B44P-NJ30](#) [K66XHT-E15S-N](#)
[K66XHT-B44S-N30](#) [K66XHT-A26P-N30](#) [K66XHT-B44S-NJ](#) [K66XHT-B44S-NJ30](#) [K66XHT-E15P-NJ30](#) [K66XHT-](#)
[B44P-N30](#) [K66XHT-A26P-NJ30](#) [K66XHT-E15S-NJ30](#) [K66XHT-E15S-N30](#) [K66XHT-E15P-N30](#) [K66XHT-E15S-NJ](#)
[K66XHT-A26S-NJ](#) [K66XHT-A26S-NJ30](#) [K66XHT-B44P-NJ](#) [K66XHT-B44S-N](#) [K66XHT-A26S-N](#) [K66XHT-A26P-NJ](#)
[K66XHT-B44P-N](#) [K66XHT-A26S-NV](#) [K66XHT-E15S-NJ99](#) [K66XHT-B44S-NVJ15](#) [K66XHT-B44P-N15](#) [K66XHT-](#)
[C62P-NV30](#) [K66XHT-C62P-NR30](#) [K66XHT-A26P-NVJ30](#) [K66XHT-C62S-NV15](#) [K66XHT-E15S-NR](#) [K66XHT-E15S-](#)
[NVJ15](#) [K66XHT-B44P-NR30](#) [K66XHT-E15P-NV](#) [K66XHT-B44P-NVJ30](#) [K66XHT-B44S-NR](#) [K66XHT-B44P-NVJ](#)
[K66XHT-E15P-NVJ15](#) [K66XHT-E15S-NR15](#) [K66XHT-C62S-NVJ15](#) [K66XHT-C62S-N15](#) [K66XHT-E15P-NVR15](#)
[K66XHT-B44P-NVR](#) [K66XHT-B44S-NV15](#) [K66XHT-E15P-NVR30](#) [K66XHT-E15S-NJ1599](#) [K66XHT-A26S-NVJ30](#)
[K66XHT-C62P-NV15](#) [K66XHT-A26P-NV](#) [K66XHT-B44S-NVJ30](#) [K66XHT-B44S-NV](#) [K66XHT-E15S-NVR15](#) [K66XHT-](#)
[C62S-NVR30](#) [K66XHT-C62S-NVJ30](#) [K66XHT-E15P-NR15](#) [K66XHT-C62P-NJ](#) [K66XHT-C62S-NVR](#) [K66XHT-B44P-](#)
[NV](#) [K66XHT-E15P-NV15](#) [K66XHT-A26S-NJ15](#) [K66XHT-C62S-N30](#) [K66XHT-C62P-NVJ15](#) [K66XHT-C62S-N](#)
[K66XHT-E15S-NV15](#) [K66XHT-E15P-NVJ](#) [K66XHT-A26P-NVR30](#) [K66XHT-C62P-NJ30](#) [K66XHT-A26P-NR15](#)
[K66XHT-B44S-NVR15](#) [K66XHT-E15S-NVJ](#) [K66XHT-E15P-NVR](#) [K66XHT-B44P-NV30](#) [K66XHT-C62P-NVR](#) [K66XHT-](#)
[E15S-N1599](#) [K66XHT-A26P-NJ15](#) [K66XHT-C62P-N15](#) [K66XHT-A26S-NVJ](#) [K66XHT-A26P-NV15](#) [K66XHT-A26P-N15](#)
[K66XHT-C62S-NR](#) [K66XHT-E15P-NV30](#) [K66XHT-E15P-NR30](#) [K66XHT-A26S-NVR](#) [K66XHT-C62P-NVR15](#)
[K66XHT-A26P-NVR](#) [K66XHT-B44P-NV15](#) [K66XHT-B44P-NR15](#) [K66XHT-C62P-NVJ30](#) [K66XHT-E15S-NVJ30](#)
[K66XHT-C62S-NVR15](#) [K66XHT-A26S-NV30](#) [K66XHT-E15P-NVJ30](#) [K66XHT-C62S-NVJ](#) [K66XHT-E15S-NV](#)
[K66XHT-B44S-NVJ](#) [K66XHT-C62P-NJ15](#) [K66XHT-B44S-NVR](#) [K66XHT-E15P-NJ15](#)