


## D-SUBMINIATURE CONNECTORS: K66XHT Series High Temperature Right Angle PCB Mount

### K66XHT Series Dimensions Dimensions in mm

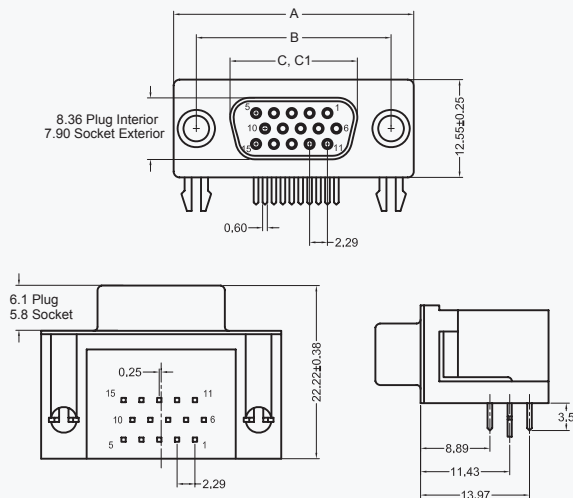

| Shell Size<br>In<br>mm | A<br>±.015<br>±0.38 | B<br>±.005<br>±0.13 | C<br>±.010<br>±0.25 | C1<br>±.010<br>±0.25 | D<br>±.005<br>±0.13 | E<br>±.005<br>±0.13 |
|------------------------|---------------------|---------------------|---------------------|----------------------|---------------------|---------------------|
| 15<br>(E)              | 1.213<br>30.81      | .984<br>24.99       | .643<br>16.33       | .666<br>16.92        | .090<br>2.29        | .010<br>0.25        |
| 26<br>(A)              | 1.541<br>39.14      | 1.312<br>33.32      | .971<br>24.66       | .994<br>25.25        | .090<br>2.29        | .020<br>0.51        |
| 44<br>(B)              | 2.088<br>53.04      | 1.852<br>47.04      | 1.511<br>38.38      | 1.534<br>38.96       | .090<br>2.29        | .020<br>0.51        |
| 62<br>(C)              | 2.729<br>69.32      | 2.500<br>63.50      | 2.159<br>54.84      | 2.182<br>55.42       | .095<br>2.41        | .023<br>0.58        |

C = Exterior of Female Shell (S)  
C1 = Interior of Male Shell (P)

|                       |                     |                      |                  |
|-----------------------|---------------------|----------------------|------------------|
| 2D Drawing            | IGES                | STEP                 | 3D PDF           |
| Solder Profile        | CofC RoHS Compliant | CofC REACH Compliant | UL Plastic File  |
| Certificate of Origin | Check Stock         | Request a Sample     | Send Us An Email |

#### Generated Part Number

#### Part Number Builder

|                      |   |                       |                      |                      |
|----------------------|---|-----------------------|----------------------|----------------------|
| <input type="text"/> | - | <input type="text"/>  | <input type="text"/> | <input type="text"/> |
| Series               |   | Shell Size<br>Contact | Contact<br>Type      | Mounting<br>Option   |

#### Series

K66XHT - Reflow Compatible Version

#### Shell Size-Contact Option

E - 15 Contacts

A - 26 Contacts

B - 44 Contacts

#### Contact Type

P - Pin Contact (Plug)

S - Socket Contact (Receptacle)

#### Mounting Option

N - With Boardlocks and #4-40 UNC Threaded Inserts

NJ - With Boardlocks and #4-40 Jackscrews Installed

Contact Kycon for VESA and Other Options

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kycon:](#)

[K66XHT-E15S-N-VESA](#)