


D-SUBMINIATURE CONNECTORS:

K86X Series

High Density Vertical PCB Mount and Solder Cup

K86X Series Dimensions

Dimensions in mm

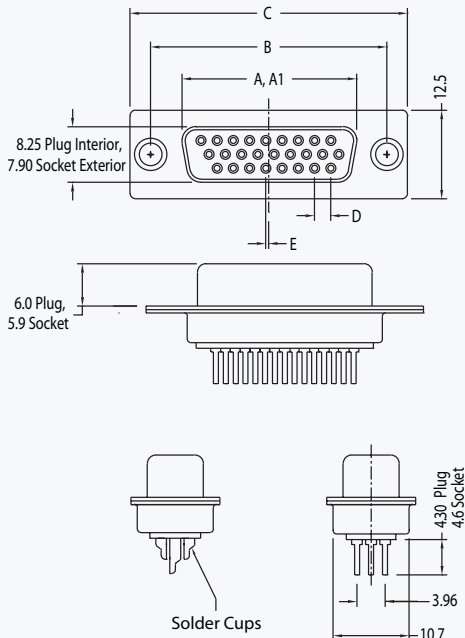

Number of Contacts (Shell Size)	Dimensions (Inch/mm)					
	A±0.35	A1±0.35	B±0.25	C±0.25	D±0.25	E±0.25
15 (E)	16.33	16.92	24.99	30.81	2.29	0.25
26 (A)	24.75	25.25	33.32	39.14	2.29	0.50
44 (B)	38.38	38.96	47.04	53.04	2.29	0.50
62 (C)	54.80	55.42	63.50	69.40	2.41	0.60

A = Exterior of Female Shell (S)

A1 = Interior of Male Shell (P)

2D Drawing	IGES	STEP	3D PDF
Solder Profile	CofC RoHS Compliant	CofC REACH Compliant	UL Plastic File
Certificate of Origin	Check Stock	Request a Sample	Send Us An Email

Generated Part Number

Part Number Builder

	-					
Series		Shell Type	Pin Type	Contact Option	Contact Type	Mounting Option
						Plating Option

Series

K86X - D-Subminiature Vertical Connector

Contact Shell Size

E - 15 Contacts

A - 26 Contacts

B - 44 Contacts

C - 62 Contacts

Contact Construction, Pin Type

A - Precision Formed, Solder Cup (Not Available with BR/BRJ)

D - Precision Formed, Vertical Pin (PCB Mount)

Contact Type

P - Pin Contact (Plug)

S - Socket Contact (Receptacle)

Mounting Option

Blank - Through Hole

BR - #4-40 Threaded Boardlocks

BRJ - #4-40 Threaded Boardlocks and #4-40 Jackscrews Installed

K - #4-40 Threaded Bushings

KJ - #4-40 Bushings and #4-40 Jackscrews

Plating Option

Blank - Gold Flash

30 - 30μ" Gold

Contact Kycon for Other Options

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kycon:](#)

[K86X-ED-15SK](#) [K86X-CD-62S-RBR](#) [K86X-ED-15S-RBR30](#) [K86XHT-ED-15S](#)