


D-SUBMINIATURE CONNECTORS:

KF66X Series

Right Angle PCB Mount With Ferrite

KF66X Series Dimensions

Dimensions in mm

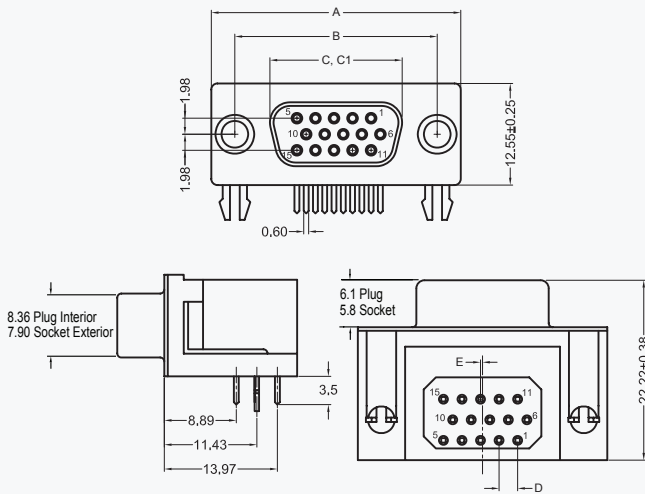

Shell Size	A	B	C	C1	D	E
In	± .015	± .005	± .010	± .010	± .005	± .005
mm	± 0.38	± 0.13	± 0.25	± 0.25	± 0.13	± 0.13
15 (E)	1.213	.984	.643	.666	.090	.010
	30.81	24.99	16.33	16.92	2.29	0.25
26 (A)	1.541	1.312	.971	.994	.090	.020
	39.14	33.32	24.66	25.25	2.29	0.51
44 (B)	2.088	1.852	1.511	1.534	.090	.020
	53.04	47.04	38.38	38.96	2.29	0.51

C = Exterior of Female Shell (S)

C1 = Interior of Male Shell (P)

Electrical Characteristics

Rated Current: 1.5A

Rated Voltage: 29Vac

2D Drawing

IGES

STEP

3D PDF

Solder Profile

CofC RoHS Compliant

CofC REACH Compliant

UL Plastic File

Certificate of Origin

Check Stock

Request a Sample

Send Us An Email

Generated Part Number

Part Number Builder

	-				
Series		Shell Size Contact	Contact Type	Mounting Option	Plating Option

Series

KF66X - High Density D-Subminiature Connector, Right Angle PCB Termination, 0.350" Footprint, with Ferrite

Shell Size-Contact Option

E - 15 Contacts

A - 26 Contacts

B - 44 Contacts

Contact Type

P - Pin Contact (Plug)

S - Socket Contact (Receptacle)

Mounting Option

N - With Boardlocks and #4-40 UNC Threaded Insert

NJ -With Boardlocks and #4-40 Jackscrews Installed

Plating Option

Blank - Gold Flash

30 - 30μ" Gold

Contact Kycon for VESA and Other Options

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Kycon:

[KF66X-B44P-N](#) [KF66X-A26S-N](#) [KF66X-E15P-NJ](#) [KF66X-A26P-N](#) [KF66X-A26S-NJ](#) [KF66X-E15S-N-VESA](#) [KF66X-E15P-N](#) [KF66X-E15S-NJ-VESA](#) [KF66X-E15S-N](#) [KF66X-B44S-N](#) [KF66X-A26P-NJ](#) [KF66X-B44S-NJ](#) [KF66X-E15S-NJ](#) [KF66X-A26P-N30](#) [KF66X-B44P-NJ30](#) [KF66X-C62P-NJ](#) [KF66X-C62S-N](#) [KF66X-C62S-NJ](#) [KF66X-B44S-N30](#) [KF66X-A26P-NJ30](#) [KF66X-E15S-NJ30](#) [KF66X-C62P-N30](#) [KF66X-A26S-N30](#) [KF66X-C62P-N](#) [KF66X-C62S-N30](#) [KF66X-A26S-NJ30](#) [KF66X-E15P-N30](#) [KF66X-B44S-NJ30](#) [KF66X-C62S-NJ30](#) [KF66X-B44P-NJ](#) [KF66X-B44P-N30](#) [KF66X-E15S-N30](#) [KF66X-C62P-NJ30](#) [KF66X-E15P-NJ30](#) [KF66X-A26S-NT15](#) [KF66X-C62S-NR30](#) [KF66X-B44P-NT](#) [KF66X-B44P-N15](#) [KF66X-E15P-NR](#) [KF66X-A26P-NT30](#) [KF66X-A26S-NR15](#) [KF66X-E15P-NV15](#) [KF66X-A26P-NVJ](#) [KF66X-A26S-NVJ30](#) [KF66X-B44S-NT15](#) [KF66X-C62P-NR](#) [KF66X-E15S-NV15](#) [KF66X-A26S-N15](#) [KF66X-B44P-NVJ](#) [KF66X-E15P-NVJ15](#) [KF66X-A26S-NT](#) [KF66X-E15P-NT15](#) [KF66X-B44P-NV](#) [KF66X-C62P-N15](#) [KF66X-E15S-NT30](#) [KF66X-C62S-NV30](#) [KF66X-A26S-NT30](#) [KF66X-E15P-NVJ30](#) [KF66X-E15S-NT](#) [KF66X-A26P-NR](#) [KF66X-C62P-NR15](#) [KF66X-E15P-NR15](#) [KF66X-E15S-NVJ](#) [KF66X-A26S-NV](#) [KF66X-B44S-NVJ](#) [KF66X-E15S-NVJ15](#) [KF66X-A26P-NV](#) [KF66X-C62P-NV15](#) [KF66X-A26S-NV30](#) [KF66X-E15S-NR-VESA](#) [KF66X-E15P-NVJ](#) [KF66X-E15P-NR30](#) [KF66X-C62S-NVJ15](#) [KF66X-B44P-NJ15](#) [KF66X-E15S-NT15](#) [KF66X-B44P-NT30](#) [KF66X-B44P-NR](#) [KF66X-E15S-NV30](#) [KF66X-A26S-NVJ](#) [KF66X-B44P-NVJ30](#) [KF66X-B44S-NT30](#) [KF66X-B44P-NVJ15](#) [KF66X-E15S-NV](#) [KF66X-A26P-NT15](#) [KF66X-E15S-NVJ30](#) [KF66X-C62S-NR](#) [KF66X-B44P-NT15](#) [KF66X-E15P-N15](#) [KF66X-B44S-NV30](#) [KF66X-E15S-N15](#) [KF66X-E15P-NJ15](#) [KF66X-C62P-NVJ15](#) [KF66X-B44S-NT](#) [KF66X-A26P-NR30](#) [KF66X-A26P-NV15](#) [KF66X-B44S-NV15](#) [KF66X-C62S-NVJ30](#) [KF66X-B44S-NVJ30](#) [KF66X-C62P-NVJ30](#) [KF66X-C62P-NV30](#)