
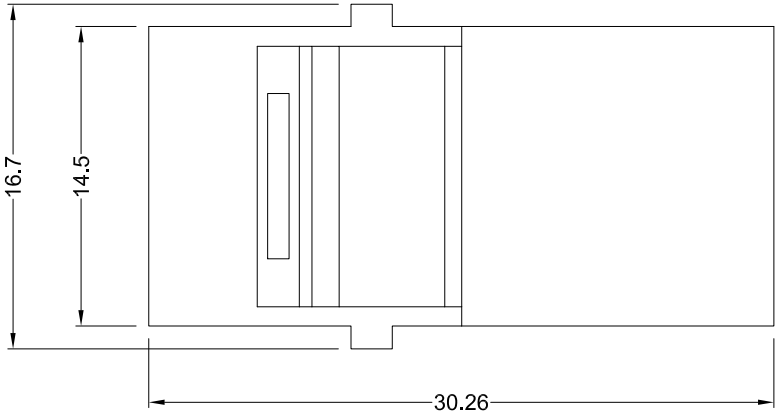
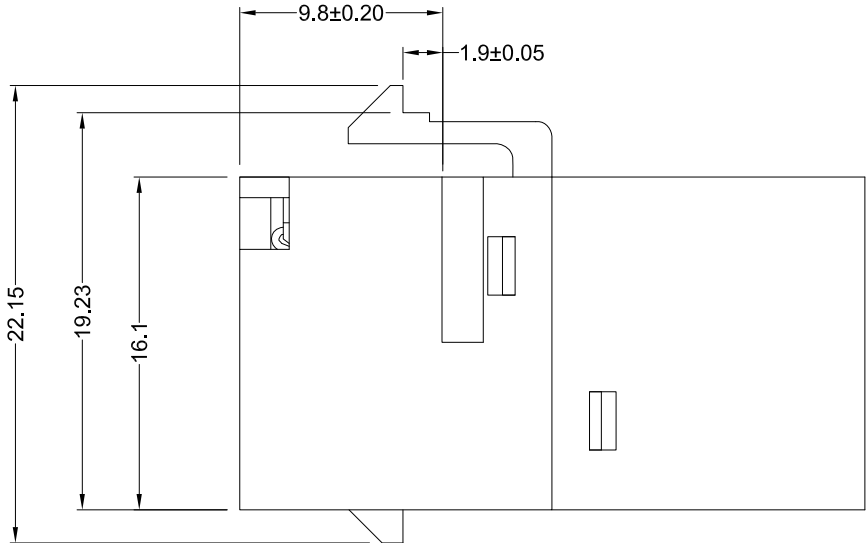


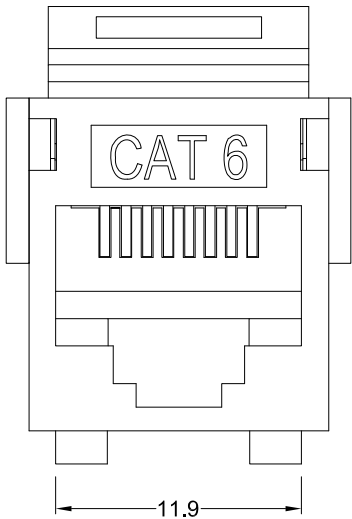

Materials and Finish

Housing: ABS Thermoplastic
UL 94V-0 Rated
Color: White

Contact Material:
Phosphor Bronze


Plating:

Nickel Underplating,
Contact Area Plated with 50u" Gold

Mechanical Characteristics

Durability Rating:
750 Mating Cycles

Operating Temperature:
-40°C to +60°C

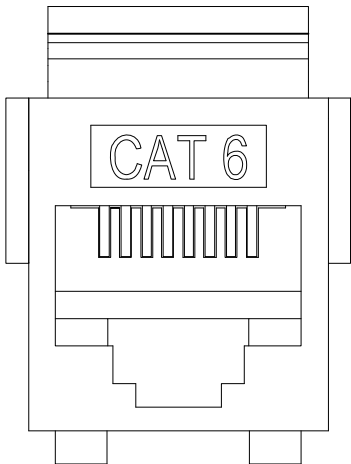

Tolerances
X.X ± 0.30
X.XX ± 0.25
Unless Stated
Otherwise



REV.	DATE	DESCRIPTION	REV. BY	CHK. BY	DRAWN BY	DATE
A0	03/26/18	New Drawing	J. Elbanna	C. Kelleher	J. Elbanna	03/26/18
A1	07/05/18	Release Drawing	G. Serrato	D. Shehan		

KLAPX-CPLR-N-88-C6

Cat 6 Modular Coupler, White Housing
8P/8C, Tab Down



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kycon:](#)

[KLAPX-CPLR-N-88-C6](#)