



UNIVERSAL SERIAL BUS: KUSBX-SL Series

Upright USB, C Type Jack, 14Pin

Product Features

Upright, Slim Profile
Compatible with Many Computer Peripherals
Supports Hot Plugging
Meets USB 2.0 and PD Specifications
Contact Area with Gold Plating

Performance Specifications

Materials and Finish

Insulator

High Temperature, UL94 V-0 Rated, Black Color

Contact Material

Copper Alloy

Plating

Gold flash plated on both contact area and soldertails with nickel under plated

Shield

Stainless Steel, Nickel plated

Electrical Characteristics

Current Rating

3A Max.

Contact Resistance

40 Milliohms Max.

Insulation Resistance

100 Megohms Min.

Dielectric withstanding Voltage

100V AC RMS for 1 Minute

Mechanical Characteristics

Insertion Force

5N - 20N

Extraction Force

8N - 20N

Durability

10000 Cycles

Operating Temperature

-30°C to 85°C

2D Drawing	IGES	STEP	3D PDF
Solder Profile	CofC RoHS Compliant	CofC REACH Compliant	UL Plastic File
Certificate of Origin	Check Stock	Request a Sample	Send Us An Email

Generated Part Number

Part Number Builder

	-			
Series		Type	Insulator Color Option	Plating Option

Series

KUSBX-SL - Upright, Universal Serial Bus

Type

CS1N14 - C Type, 14 Pin

Insulator Color Option

B - Black

Plating Option


Blank - Gold Flash

30 - 30 μ "Gold

Contact Kycon for other options

KUSBX-SL

Dimensions in mm

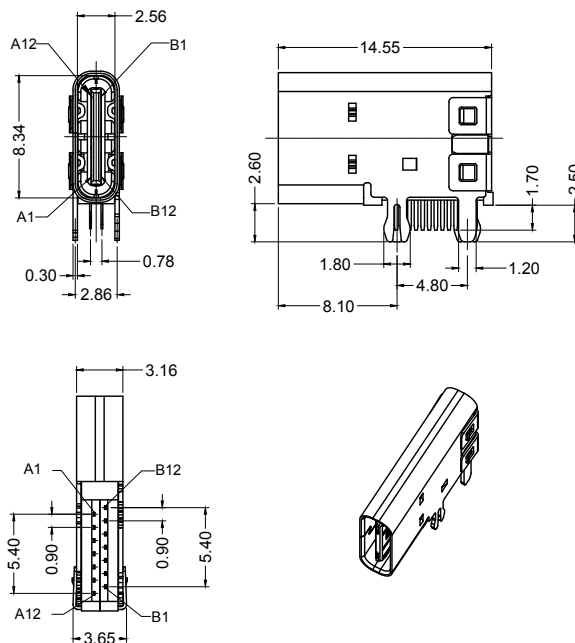

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kycon:](#)

[KUSBX-SL-CS1N14-B](#)