


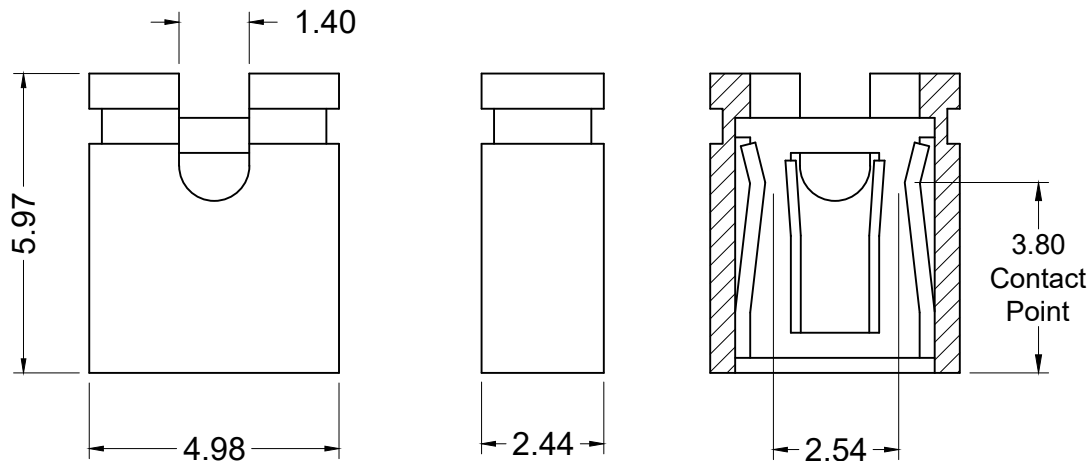

B Type

Materials and Finish

Body: PBT Thermoplastic,
30% glass filled,
UL94V-0 rated,
black color

Contact Material: Brass,
Whole Terminal Nickel Plated, With
Gold Flash Plated In Contact Area

Electrical Specifications

Contact Current Rating:
3 Amp Max.

Contact Resistance:
20 milliohms Max.

Dielectric Withstanding Voltage:
AC 650 Volts RMS

Insulation Resistance:
1000 Megohms Min.


Temperature Rating:
-55°C To +125°C

Tolerances

X.X ± 0.25
X.XX ± 0.15
Unless Stated
Otherwise

RoHS COMPLIANT

REV.	DATE	DESCRIPTION	REV. BY	CHK. BY	DRAWN BY	DATE
A1	6/30/05	New Drawing	H. MA	C. Furumasu	H. MA	6/30/05
A2	09/23/10	ECO #10-065	S. Vien	H. MA		
A3	08/13/18	Update Address	D.Shehan	N/A		
A4	01/31/19	ECO #19-012	C. Kelleher	D.Shehan		

 

SX1100-B

Mini Shunt, 2.54 mm Pitch

RoHS Compliant



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kycon:](#)

[SX1100-B](#)