



THERMAL IMAGING MONOCULAR

FLIR SCOUT TK®

The FLIR Scout TK is a pocket-sized thermal vision monocular for exploring the outdoors at night and in lowlight conditions. Scout TK reveals your surroundings and helps you see people, objects, and animals over 100 yards (90 m) away. Simple to use, with still image and video recording, Scout TK is the perfect companion, whether in the back country or your own backyard.

www.flir.com



STAY AWARE, STAY SAFE

Use for personal home security at night

- Keep an eye on your property 24/7
- Search for missing pets, check for predators
- Scan sidewalks, parking lots, & parks in the dark
- 5-hour Rechargeable Li-Ion battery



EXPLORE LIKE NEVER BEFORE

Find wildlife, stay aware in the dark

- See animals/people over 100 yards away
- Pocket-sized, light-weight (6 oz. / 170 g)
- Rugged design withstands bumps and splashes
- Records video and still images to share with others



GRAB AND GO SIMPLICITY


Starts up in seconds, no training required

- Single-handed operation
- Simple four-button design and intuitive interface
- Multiple video color palettes to enhance viewing: (White/Black Hot, InstAlert™, Graded Fire, and more)

SPECIFICATIONS

General		SCOUT TK
Detector Type		160 × 120 VOx Microbolometer
Video Refresh Rate		<9Hz
Field of View (H x V)		20° × 16°
Shutter		Yes
Start up		< 5 seconds/Image
Image Processing		FLIR Proprietary Digital Detail Enhancement
User Interface		
Power Button		On/Off
Video Detection Palettes		Short Press to Toggle thru LUT's
Brightness		Brightness (Toggle up->down)
Image Capture		Short press for Image capture, long press for Video capture
Image Download		USB Cable
Image Presentation		
Built-In Display		640 X 480 LCD Display
Color Palettes		Selectable: Black Hot, White Hot, InstAlert™ Rainbow, Iron, Lava, Arctic & Graded FirePOWER
Power		
Battery type		Internal Li-Ion Cell
Battery life (operating)		>5 hours
Environmental		
Operating temperature range		-20°C to +40°C (-4°F to +104°F)
Storage temperature range		-40°C to +60°C (-40°F to +140°F)
Physical		
Weight		0.17 kg (0.37 lbs)
Overall dimensions		101 × 38 × 38 mm (4,0 × 1.5 × 1.5 in)
Package includes		

Handheld Thermal Camera, Neck Lanyard, USB Cable, Lens Cap

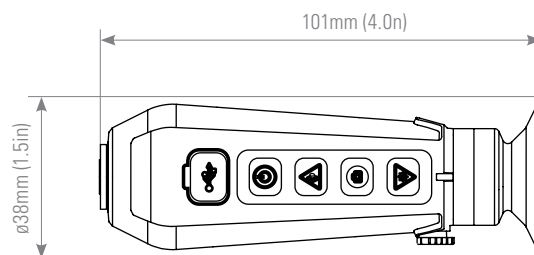

Specifications are subject to change without notice.
For the most up-to-date specs, go to www.flir.com

FLIR OUTDOOR & TACTICAL SYSTEMS

9 Townsend West,
Nashua, NH 03063

Phone: 1-888-959-2259
or (603) 324-7600
Fax: 1-888-959-2260

FLIR PRODUCT REPAIR CENTER

email: US_CBUrepair@flir.com
Register on: customer.flir.com

ORDER PLACEMENT, RETURN TO STOCK & INQUIRIES

email: OTS-Orders@flir.com

PRODUCT REGISTRATION

flir.com/support-center/support-hq/

TECHNICAL SUPPORT

email: US_CBUsupport@flir.com

www.flir.com
NASDAQ: FLIR

Equipment described herein may require US Government authorization for export purposes. Diversion contrary to US law is prohibited. Imagery for illustration purposes only. Specifications are subject to change without notice, check our website: www.flir.com
©2018 FLIR Systems, Inc. All rights reserved.
Updated 11/22/2018

18-2265-OTS



The World's Sixth Sense™

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Teledyne FLIR:](#)

[Scout TK](#)