 


Datasheet

LL01CR-CHQxxL02

Available Distribution




LED

 CREE CXA1304	 CREE CXA1512	 CREE MHB	 CITIZEN CLL010	 CITIZEN CLL010	 LUMILEDS LUXEON M	 LUMILEDS L2C5-1202E0600
 LUMILEDS L2C5-1203x0900	 LUMINUS CXM-6	 TOYONIA M04	 TOYONIA M05	 TOYONIA M10	 XICATO XTM 9mm	

Recommend Applications



 General Information




- Lens Material PC LEV1700KL
- Operating Temperature -40°C~+110°C
- UL Flammability V-2 @1.5mm
- UL RTI Elec 130°C @1.5mm
- Light Transmission Rate 400nm~900nm > 90%
- ✓ If necessary, Clean lenses with mild soap, water and soft cloth.
- ⚠ Never use any commercial cleaning solvents on lenses, like alcohol.
- ⚠ Please handle or install lenses with wearing gloves, skin oils may damage lens or its optical characteristic.

Dimensions

Part Number	Diameter	Height
LL01CR-CHQxxL02	Ø35	10.5

*All dimensions are in millimeters.

Packaging Details (SPQ)

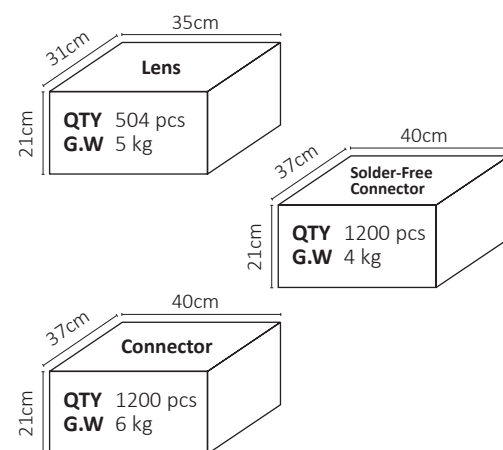

Accessories




- Available with Connector LL01A00CSLB2 / LL01A00CWIB2 / LL01A00CXB2
- Available with Solder-Free Connector LL01A00CWFB2 / LL01A00CXTB2 LL01A00CWGB2 / LL01A00CXPB2

Mechanical Specification

*All dimensions are in millimeters.


Lens Dimension

LL01CR-CHQ××L02

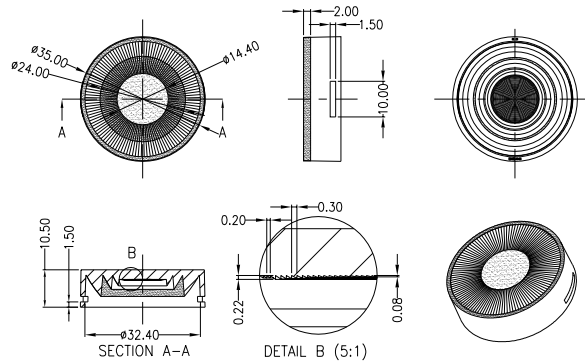

Solder-Free Connector Dimension

LL01A00CWFB2 (Material: PBT 4815 / RTI:75)
LL01A00CXTB2 (Material: CCP PBT 5815F-200 / RTI:130)

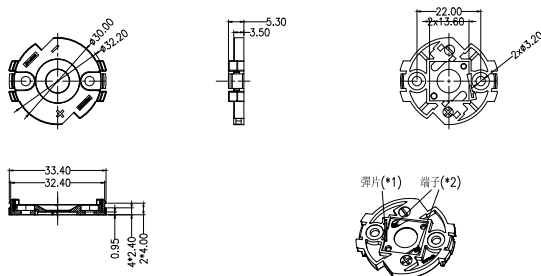



Assembly Instruction

Part No LL01CR-CHQ××L02
Connector LL01A00CWFB2 / LL01A00CXTB2
LED CREE CXA1304

Fixing Method




 Luminarie Accessories

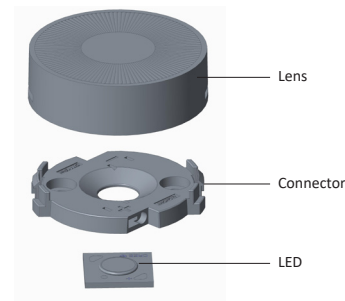

Solder-Free Connector Dimension

LL01A00CWGB2 (Material: PBT 4815 / RTI:75)
LL01A00CXPB2 (Material: CCP PBT 5815F-200 / RTI:130)

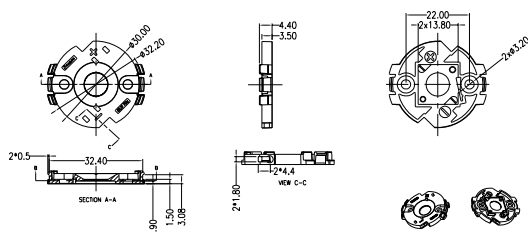



Assembly Instruction

Part No LL01CR-CHQ××L02
Connector LL01A00CWGB2 / LL01A00CXPB2
LED Citizen CLU700 / LUMINUS CXM-6

Fixing Method



 
Luminarie Accessories

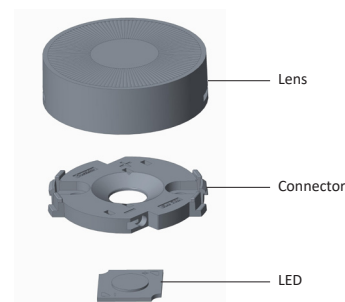

Connector Dimension



LL01A00CSLB2 (Material: PBT 4815 / RTI:75)
 LL01A00CWIB2 (Material: PBT 4115 / RTI:120)
 LL01A00CXOB2 (Material: CCP PBT 5815F-200 / RTI:130)

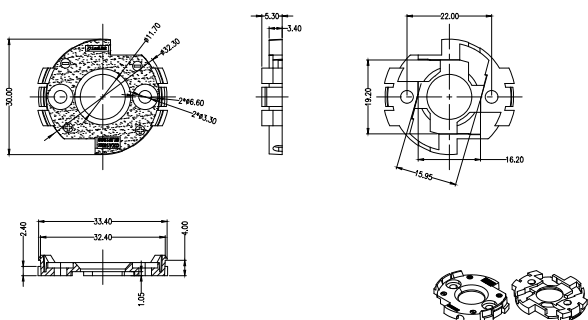


Assembly Instruction

Fixing Method

Part No LL01CR-CHQxxL02
 Connector LL01A00CSLB2 / LL01A00CWIB2 / LL01A00CXOB2
 LED CREE CXA1512



Luminarie
Accessories

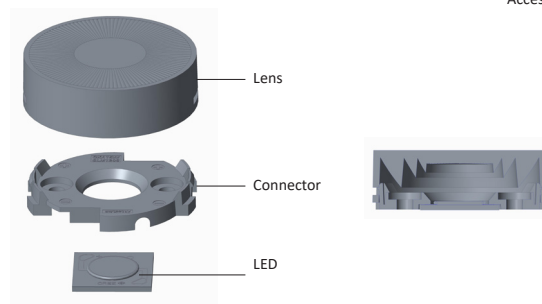


Assembly Instruction

Fixing Method

Part No LL01CR-CHQxxL02
 LED TOYONIA M10-H-30H / M05-H-30J1
 LUMILEDS LUXEON M



Luminarie
Accessories

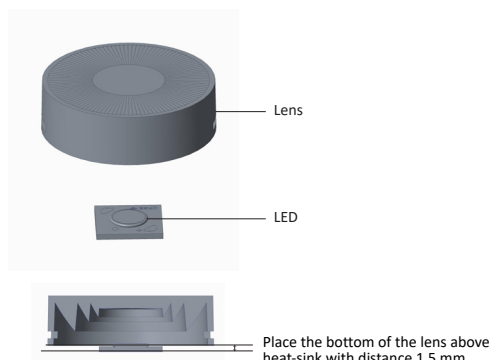


Assembly Instruction

Fixing Method

Part No LL01CR-CHQxxL02
 LED CITIZEN CLL010
 LUMILEDS Luxeon L2C5-1202E0600
 LUMILEDS Luxeon L2C5-1203x0900



Luminarie
Accessories

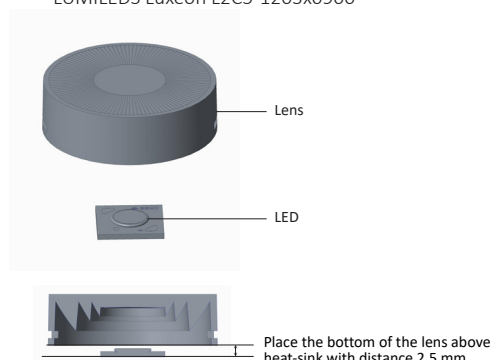


Assembly Instruction

Fixing Method

Part No LL01CR-CHQxxL02
 LED TOYONIA M04-H-27GB



Luminarie
Accessories

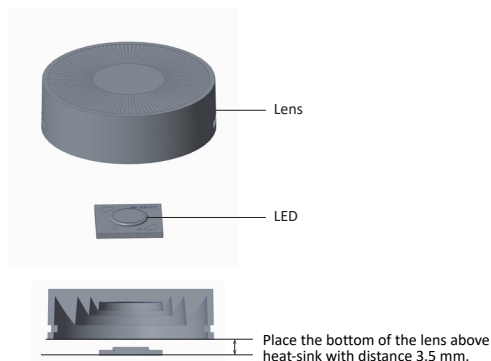


Assembly Instruction

Fixing Method


Part No LL01CR-CHQxxL02
 LED Xicato XTM-9mm



Luminarie
Accessories

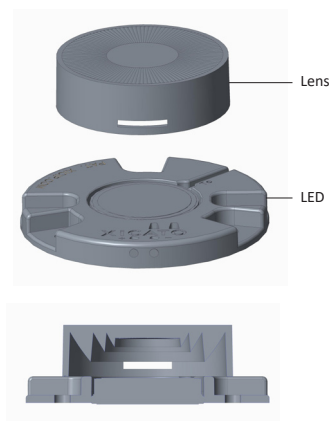

Photometric Distribution

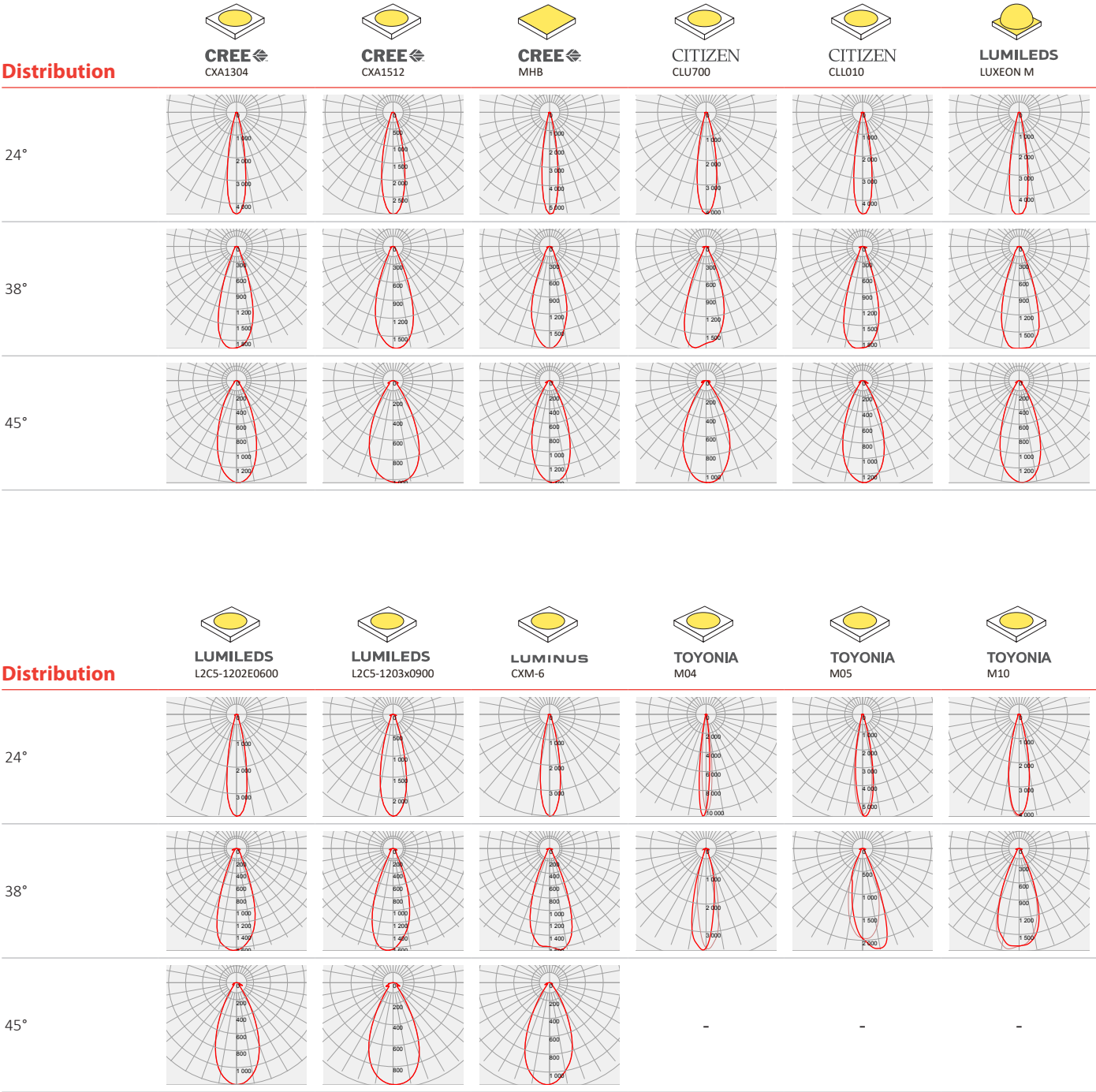


Photometric Distribution




XICATO
XTM 9mm

Distribution


24°

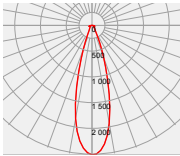


38°

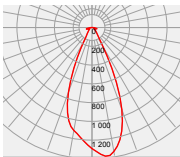

45°

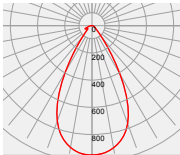

Details by LED

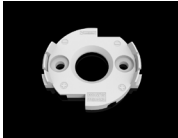Part No	Connector	LED Package Size	LED
LL01CR-CHQ××L02	-	LES Ø2.8~9	 CREE  MHB  CITIZEN CLL010  LUMILEDS L2C5-1202E0600  LUMILEDS L2C5-1203x0900  LUMILEDS LUXEON M  TOYONIA M04  TOYONIA M05  TOYONIA M10  XICATO XTM 9mm
Solder-Free  LL01A00CWFB2 LL01A00CXTB2		LES Ø6	 CREE  CXA1304
Solder-Free  LL01A00CWGB2 LL01A00CXPB2		LES Ø6~7.8	 CITIZEN CLU700  LUMINUS CXM-6
 LL01A00CSLB2 LL01A00CWIB2 LL01A00CXOB2		LES Ø9	 CREE  CXA1512

LED	Part No	FWHM	cd / lm	IES
 CREE CXA1304	LL01CR-CHQ24L02	19°	4.4	
	LL01CR-CHQ38L02	35°	1.9	
	LL01CR-CHQ45L02	42°	1.4	
 CREE CXA1512	LL01CR-CHQ24L02	25°	3.0	
	LL01CR-CHQ38L02	39°	1.7	
	LL01CR-CHQ45L02	51°	1.0	
 CREE MHB	LL01CR-CHQ24L02	17°	5.5	
	LL01CR-CHQ38L02	37°	1.8	
	LL01CR-CHQ45L02	41°	1.4	
 CITIZEN CLU700	LL01CR-CHQ24L02	21°	4.2	
	LL01CR-CHQ38L02	39°	1.7	
	LL01CR-CHQ45L02	50°	1.0	
 CITIZEN CLL010	LL01CR-CHQ24L02	19°	4.6	
	LL01CR-CHQ38L02	34°	1.9	
	LL01CR-CHQ45L02	44°	1.3	
 LUMILEDS LUXEON M	LL01CR-CHQ24L02	19°	4.8	
	LL01CR-CHQ38L02	36°	1.7	
	LL01CR-CHQ45L02	42°	1.4	
 LUMILEDS L2CS-1202E0600	LL01CR-CHQ24L02	21°	3.8	
	LL01CR-CHQ38L02	38°	1.6	
	LL01CR-CHQ45L02	46°	1.2	
 LUMILEDS L2CS-1203x0900	LL01CR-CHQ24L02	27°	2.4	
	LL01CR-CHQ38L02	38°	1.6	
	LL01CR-CHQ45L02	52°	0.9	
 LUMINUS CXM-6	LL01CR-CHQ24L02	21°	4.0	
	LL01CR-CHQ38L02	40°	1.6	
	LL01CR-CHQ45L02	49°	1.1	
 TOYONIA M04	LL01CR-CHQ24L02	11°	10.7	
	LL01CR-CHQ38L02	23°	3.6	
	LL01CR-CHQ45L02	-	-	-
 TOYONIA M05	LL01CR-CHQ24L02	19°	5.7	
	LL01CR-CHQ38L02	33°	2.2	
	LL01CR-CHQ45L02	-	-	-
 TOYONIA M10	LL01CR-CHQ24L02	22°	4.2	
	LL01CR-CHQ38L02	42°	1.7	
	LL01CR-CHQ45L02	-	-	-
 XICATO XTM 9mm	LL01CR-CHQ24L02	28°	2.5	
	LL01CR-CHQ38L02	44°	1.3	
	LL01CR-CHQ45L02	56°	0.9	

Product Nomenclature

Ledlink Led Type Lens Angle
LL 01 CR -CHQ 24 L02
Lens Dot Number Serial Number Type of Material

Ledlink Optics, Inc

Taiwan HQ

15F, No.655,Bannan Rd., Chung-Ho Dist.,
New Taipei City, Taiwan 235

Ledlink Optics (Dongguan) Co., Ltd

Dongguan Factory

No.5, TianKeng Industrial Dist., HengLi Town, DongGuan City,
GuangDong Province, China 523478

Ledlink Optics (Yangzhou) Co., Ltd

Yangzhou Factory

No.180, LinJiang Rd., YangZhou City, Jiangsu Province, China 225009

www.ledlink-optics.com

service@ledlink-optics.com



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LedLink Optics:](#)

[LL01CR-CHQ45L02](#)