 





Datasheet

LL01BR-ETJxxL191-M2

Available Distribution



 LED



Recommend Applications



General Information




- Lens Material PMMA 20HR
- Operating Temperature -40°C~+70°C
- UL Flammability HB @1.5mm
- UL RTI Elec 50°C @1.5mm
- Light Transmission Rate 400nm~900nm > 90%
- ✓ If necessary, Clean lenses with mild soap, water and soft cloth.
- ⚠ Never use any commercial cleaning solvents on lenses, like alcohol.
- ⚠ Please handle or install lenses with wearing gloves, skin oils may damage lens or its optical characteristic.

Dimensions

Part Number	Diameter	Height
LL01BR-ETJxxL191-M2	Ø62	18.3

*All dimensions are in millimeters.

Packaging Details (SPQ)

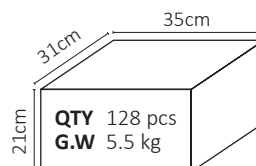

Accessories




- Available with Holder LL01ZZADX01H2
- Available with Connector LL01A00CYPB2 LL01A00CYTB2

Mechanical Specification

*All dimensions are in millimeters.


Lens Dimension

LL01BR-ETJxxL191

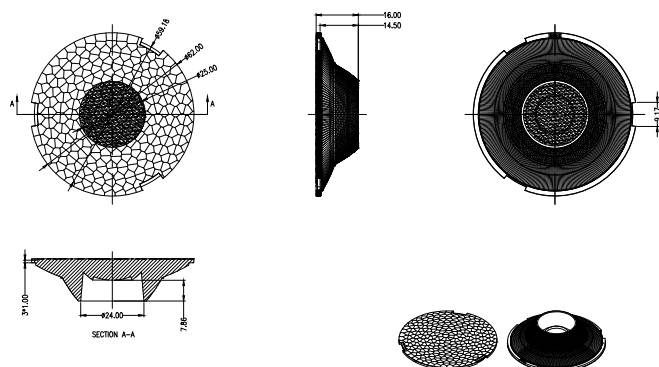


Holder Dimension

LL01ZZADX01H2

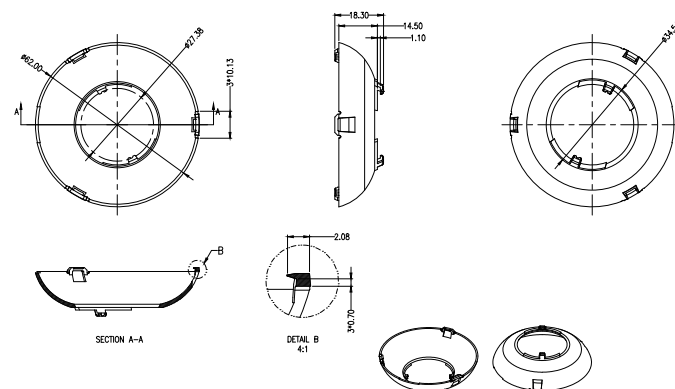


Connector Dimension

LL01A00CYPB2

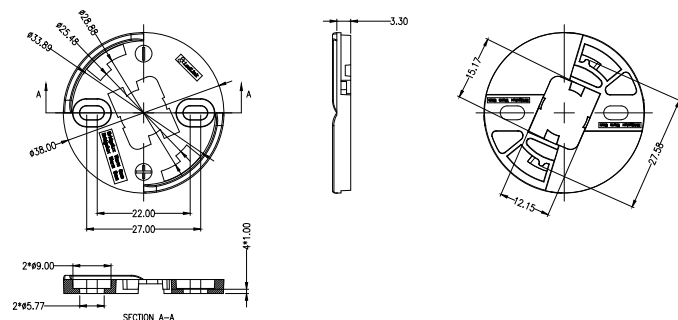

Connector Dimension



LL01A00CYTB2

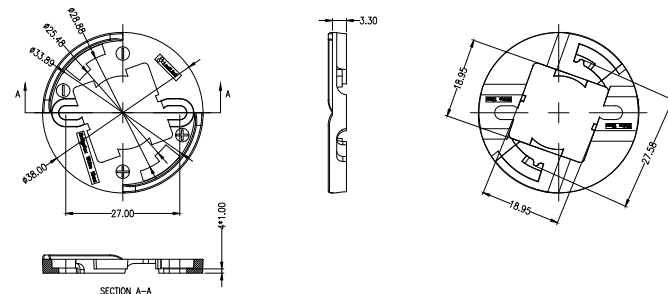

Assembly Instruction

Fixing Method

Part No LL01BR-ETJxxL191-M2
Holder LL01ZZADX01H2
Connector LL01A00CYPB2 / LL01A00CYTB2
LED Bridgelux DTW 9mm / TW 13mm

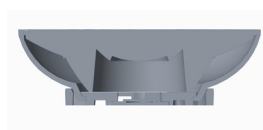
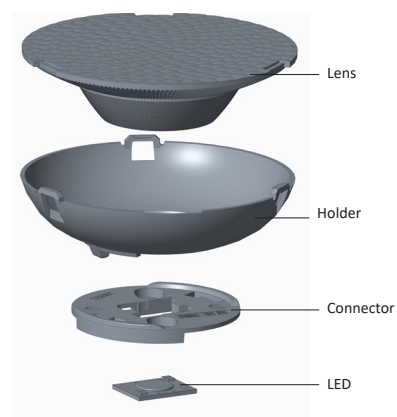


Photometric Distribution



LED



24°

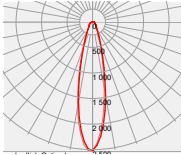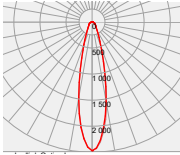

38°

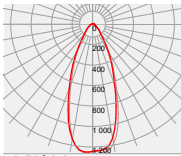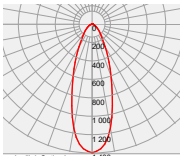

Details by LED

Part No	Holder	Connector	LED Size	LED
LL01BR-ETJxxL191-M2	 LL01ZZADX01H2	 LL01A00CYPB2	LES Ø9.3	 bridgelux. Vesta DTW 9mm
		 LL01A00CYTB2	LES Ø14.3	 bridgelux. Vesta TW 13mm

LED	Part No	FWHM	cd / lm	IES
 bridgelux. Vesta DTW 9mm	LL01BR-ETJ24L191-M2	23°	2.4	
	LL01BR-ETJ38L191-M2	35°	1.3	
 bridgelux. Vesta TW 13mm	LL01BR-ETJ24L191-M2	23°	2.5	
	LL01BR-ETJ38L191-M2	41°	1.2	

Product Nomenclature

Ledlink Led Type Lens Angle Holder
LL 01 BR- ETJ 24 L191- M2
Lens Dot Number Serial Number Type of Material

Ledlink Optics, Inc

Taiwan HQ

15F, No.655,Bannan Rd., Chung-Ho Dist.,
New Taipei City, Taiwan 235

Ledlink Optics (Dongguan) Co., Ltd

Dongguan Factory

No.5, TianKeng Industrial Dist., HengLi Town, DongGuan City,
GuangDong Province, China 523478

Ledlink Optics (Yangzhou) Co., Ltd

Yangzhou Factory

No.180, LinJiang Rd., YangZhou City, Jiangsu Province, China 225009

www.ledlink-optics.com

service@ledlink-optics.com



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LedLink Optics:](#)

[LL01BR-ETJ38L191-M2](#) [LL01A00CYTB2](#) [LL01BR-ETJ24L191-M2](#)