

SUMMARY

Wires

Coax	1
------	---

Image is for illustrative purpose only

Series	0A
Termination type	Coupler/adaptor/bridge
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	0.00 - 0.00 mm
Status	active

Download

[Request a quote](#)[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	ABA*: Adapter from LEMO receptacle to BNC plug
Keying	
Housing Material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Weight	17.78 g

Performance

Configuration	0A.250 : 1 Coax (50 Ohm)
Insulator	
Rated Current	

Specifications


Contact Type: Solder

Others

Endurance (Shell): >1000 mating cycles
Salt Spray Corrosion: >144 hr

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

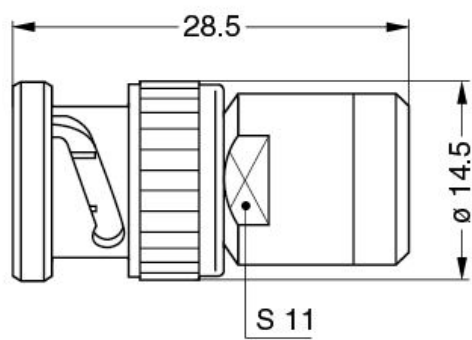

Dimensions

	A	L	S1
mm.	14.5	28.5	11
in.	0,57	1,12	0,43

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[ABA.0A.250.NTL](#)