

## SUMMARY

### # Wires



*Image is for illustrative purpose only*

Series	1F
Termination type	No contacts / Accessory
IP rating	67
AWG wire size	0.00 - 0.00
Cable Ø	3.80 - 10.70 mm
Status	active

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model	BFN*: Cap for plug (N key)
Keying	3 keys (beta=165, gamma=30, plug: male contacts, receptacle: female contacts)
Housing Material	
Weight	1.13 g


### Performance

Configuration
Insulator
Rated Current

### Others

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# DRAWINGS

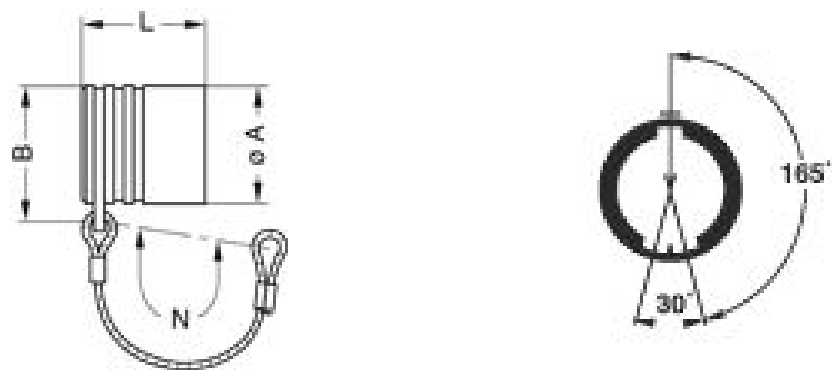

## Dimensions

	A	B	L	N
mm.	12	13.3	12.6	62
in.	0,47	0,52	0,50	2,44

# RECOMMENDED BY LEMO

## Tools

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[BFN.1F.100.PCSG](#)