

## SUMMARY

### # Wires



*Image is for illustrative purpose only*

Series	3V
Termination type	No contacts / Accessory
IP rating	68
AWG wire size	0.00 - 0.00
Cable Ø	0.00 - 0.00 mm
Status	active

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model	BRF*: Cap for free receptacle
Keying	No keying
Housing Material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Weight	33.16 g

### Performance

Configuration
Insulator
Rated Current


### Others

Endurance (Shell): 1000 mating cycles
Temp (min / max): -20°C / +135°C
Climatical Category: 20/200/21
Shielding (min): 95 dB (10 MHz)
Shielding (min): 80 dB (1 GHz)

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Salt Spray Corrosion: >144 hr  
Pressure: 30 bars

# DRAWINGS

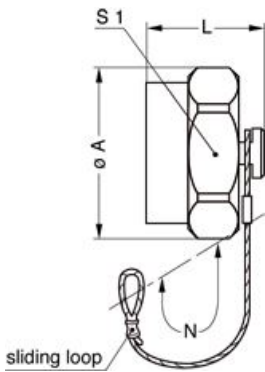

No keying

## Dimensions

	A	L	N	S1
mm.	27.8	14.7	120	26
in.	1,09	0,58	4,72	1,02

# RECOMMENDED BY LEMO

## Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[BRF.3V.200.NAV](#)