

SUMMARY

Wires

High voltage 5



Image is for illustrative purpose only

Series	2P
Termination type	Female solder
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	0.00 - 0.00 mm
Status	active
Matching parts	CAB.H05.GLA.C72A

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	CK*: Fixed receptacle with two nuts (back panel mounting)
Keying	
Housing Material	PSU (Polysulfone), gray
Weight	4.68 g

Performance

Configuration	2P.H05 : 5 High Voltage
Insulator	
Rated Current	8 Amps

Specifications


Test voltage contact-contact : 11.6 kV rms
Air clearance min.: 7.96 mm
Creepage distance min.: 7.96 mm

Others

Temp (min / max): -50°C / +150°C

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

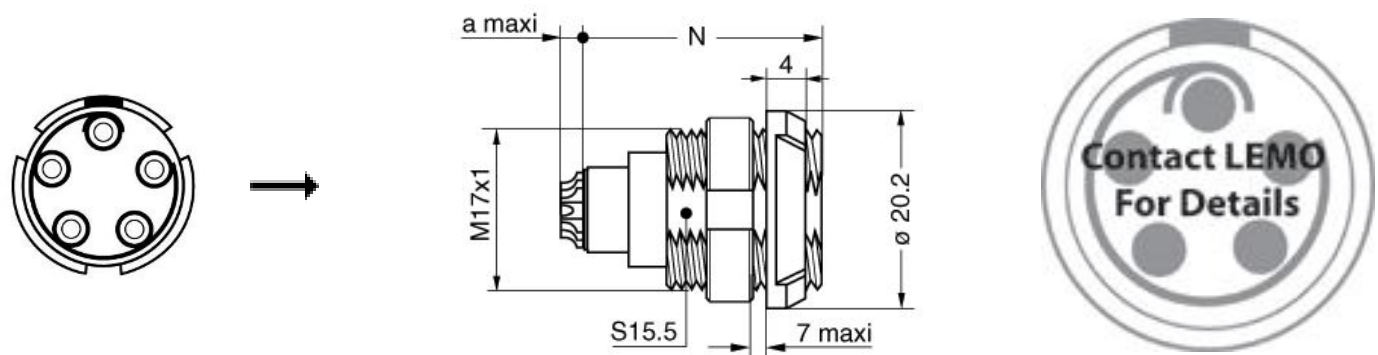

Dimensions

	N	a
mm.	23.8	3.4-4.9
in.	0,94	0,13

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[CKB.H05.GLLA](#)