

## SUMMARY

### # Wires



*Image is for illustrative purpose only*

#### Series

Termination type No contacts / Accessory

IP rating 0

AWG wire size 0.00 - 0.00

Cable Ø 0.00 - 0.00 mm

Status active

#### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model DCP\*: Set of flat spanners for FS retaining ring & collet nuts

Keying No keying

Housing Material

Weight 106.71 g

### Performance

Configuration


Insulator

Rated Current

### Others

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# DRAWINGS

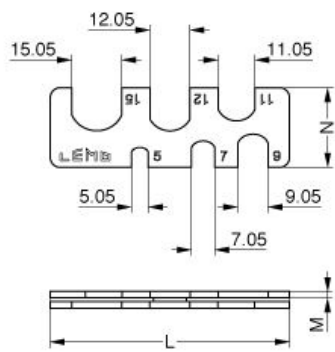

No keying

## Dimensions

	L	M	N
mm.	72	2	24
in.	2,83	0,08	0,94

# RECOMMENDED BY LEMO

## Tools

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[DCP.91.FSG.TN](#)