

## SUMMARY

### # Wires

Low voltage 37



*Image is for illustrative purpose only*

Series	0R
Termination type	Female crimp
IP rating	50
AWG wire size	32.00 - 28.00
Cable Ø	1.60 - 6.20 mm
Status	active
Matching parts	<a href="#">FGG.0R.337.GLC62</a>

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model	EBG*: Fixed receptacle, key (G) or key (A) with visible shell
Keying	3 keys (alpha=50,beta=30, plug: male contacts, receptacle: female contacts)
Housing Material	Crastin® PBT (Polybutylene terephthalate), gray
Weight	6.34 g

### Performance

Configuration	0R.337 : 37 low voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated Current	0.5 Amps


### Specifications

Contact Type: Crimp  
Test voltage (kV rms) Contact-contact: 0.6

### Others

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# DRAWINGS

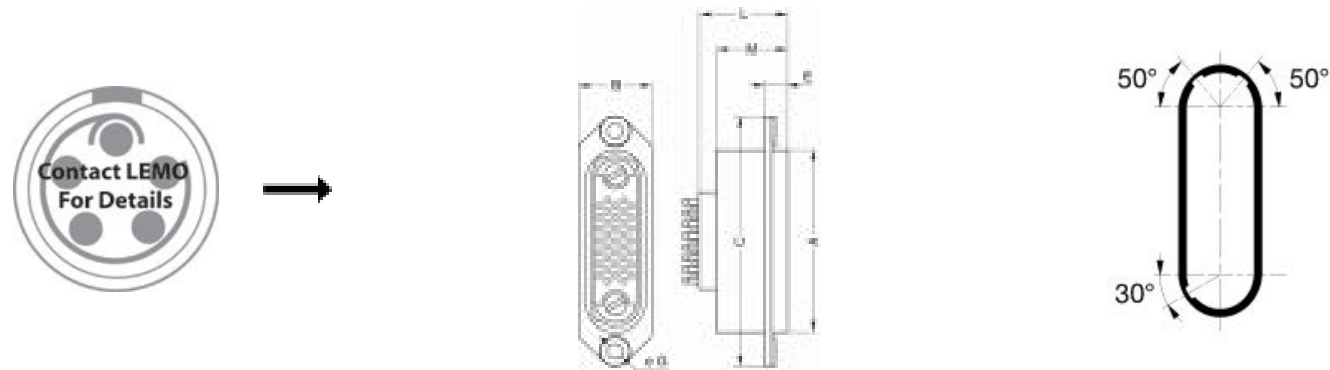

## Dimensions

	A	B	L	M
mm.	18	6	12	7
in.	0,71	0,24	0,47	0,28

# RECOMMENDED BY LEMO

## Tools

- Crimp Tool: [DPC.91.701.V](#)
- Crimp settings: AWG/Selector = 28-30-32/4-3-3
- Positionner: [DCE.91.050.0VM](#)
- Replacement contact: EGG.00.654.ZZM

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LEMO:](#)

[EBG.0R.337.GLM](#)