

SUMMARY

Wires

Low voltage	4
Coax	4



Image is for illustrative purpose only

Series	0R
Termination type	Female crimp
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	1.60 - 6.20 mm
Status	active
Matching parts	FGG.0R.804.GLC4162

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	EBG*: Fixed receptacle, key (G) or key (A) with visible shell
Keying	3 keys (alpha=50,beta=30, plug: male contacts, receptacle: female contacts)
Housing Material	Crastin® PBT (Polybutylene terephthalate), gray
Weight	11.57 g

Performance

Configuration	0R.804 : 4 Coax (50 Ohm), 4 Low V.
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated Current	2.0 Amps


Specifications

Impedance:	50
Test Voltage (kV rms):	1.35

Others

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

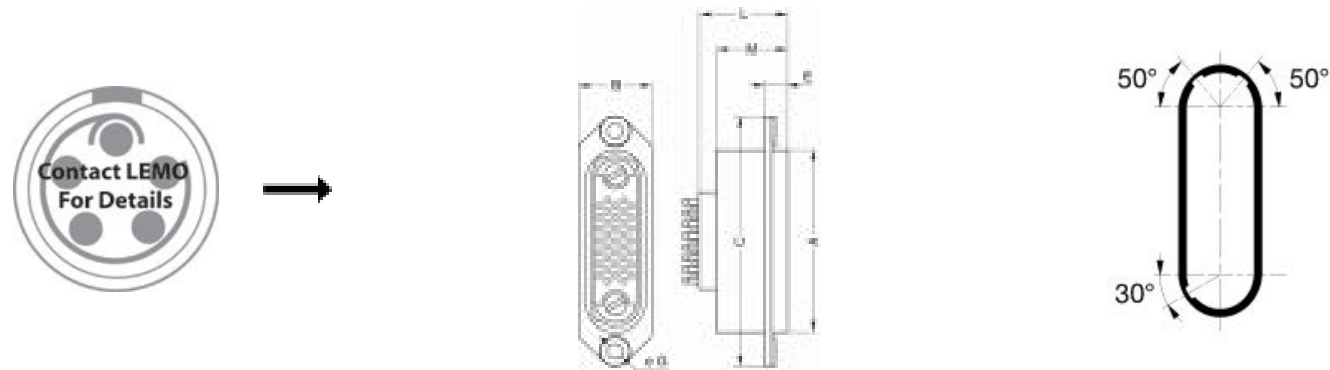

Dimensions

	A	B	L	M
mm.	18	6	12	7
in.	0,71	0,24	0,47	0,28

RECOMMENDED BY LEMO

Tools

- Crimp Tool: [DPC.91.701.V](#)
- Crimp Tool 2: [DPE.99.003.1K](#)
- Crimp settings: AWG/Selector = 22-24-26/6-5-5
- Positionner: [DCE.91.070.BVM](#)
- Replacement contact: EGG.0B.655.ZZM

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[EBG.0R.804.GLM41](#)