

## SUMMARY

### # Wires

Coax	1
------	---



*Image is for illustrative purpose only*

Series	01
Termination type	Female solder
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	0.00 - 0.00 mm
Status	active

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model	ECP.01*: Fixed receptacle, nut fixing (back panel mounting)
Keying	Circular, female
Housing Material	Brass (nickel plated [SAE AMS QQ N 290]) shell, collet nut, latch sleeve and mid pieces
Weight	1.04 g

### Performance

Configuration	01.250 : 1 Coax (50 Ohm)
Insulator	
Rated Current	

### Specifications


Contact Type: Solder

### Others

Endurance (Shell): 1000 mating cycles  
Salt Spray Corrosion: >144 hr

*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*

# DRAWINGS

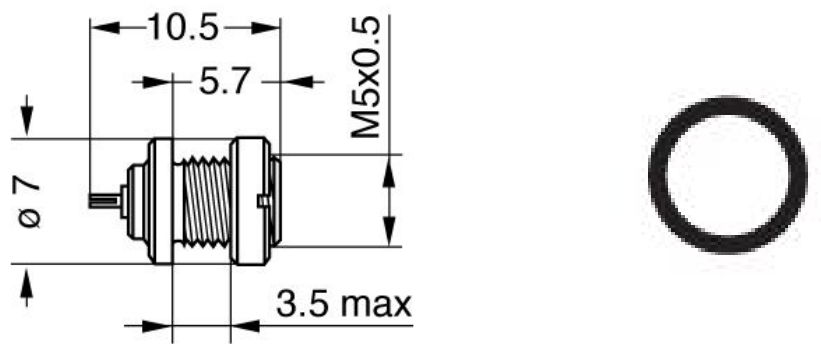

## Dimensions

	A	E <sub>max</sub>	L	M	e
mm.	7	3.5	10.5	5.7	M5x0.5
in.	0,28	0,14	0,41	0,22	

# RECOMMENDED BY LEMO

## Tools

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[ECP.01.250.NLL](#)