

SUMMARY

Wires

| | |
|--------------|----|
| Low voltage | 40 |
| High voltage | 1 |



Image is for illustrative purpose only

| | |
|------------------|---------------------|
| Series | 5B |
| Termination type | Female crimp Hybrid |
| IP rating | 50 |
| AWG wire size | 0.00 - 0.00 |
| Cable Ø | 0.00 - 0.00 mm |
| Status | active |

Download

[Request a quote](#)

TECHNICAL DETAILS

Mechanics

| | |
|-------------------|---|
| Shell Style/Model | EG*: Fixed receptacle, nut fixing |
| Keying | 5 keys (alpha=95, beta=115, gamma=20, delta=30, plug: male contacts, receptacle: female contacts) |
| Housing Material | Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces |
| Weight | 398.18 g |

Performance

| | |
|---------------|---|
| Configuration | 5B.740 : 1 High Voltage, 40 Low Voltage |
| Insulator | L: PEEK (UL 94 / V-0/1.5) |
| Rated Current | 4.5 Amps |

Specifications


| |
|--|
| Contact Type: Crimp |
| Test voltage contact-contact : 1.15 kV rms |
| Test voltage contact-body shell : 1.55 kV rms |
| Test voltage contact-inner high voltage plug shell : 1.8 kV rms |
| Test voltage for the inner high voltage plug : 10.5 kVdc, 7.5 kV rms |

Others

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Endurance (Shell): 5000
Temp (min / max): -55°C / +250°C
Humidity (max): <=95% [at 60 deg C / 140 F]
Vibration: 15 g [10 Hz - 2000 Hz]
Shock Resistance: 100 g [6 ms]
Climatical Category: 50/175/21
Shielding (min): 75 dB (10 MHz)
Shielding (min): 40 dB (1 GHz)
Salt Spray Corrosion: >1000 hr

DRAWINGS

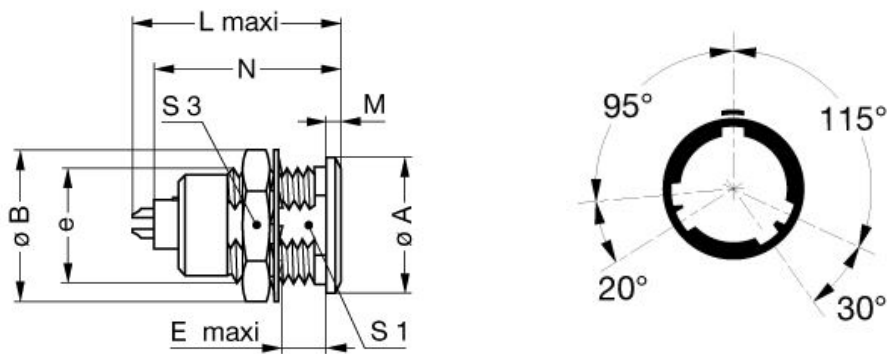

Dimensions

| | A | B | E | L | M | N | S1 | e |
|-----|------|------|------|------|------|------|------|---------|
| mm. | 40 | 40 | 11 | 43.5 | 3 | 39.6 | 33.5 | M35x1.0 |
| in. | 1,57 | 1,57 | 0,43 | 1,71 | 0,12 | 1,56 | 1,32 | |

RECOMMENDED BY LEMO

Tools

Positionner: [DCE.91.095.BVM](#)
Extractor: [DCF.91.093.5LT](#)

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[EGR.5B.740.CLM6](#)