

## SUMMARY

### # Wires



*Image is for illustrative purpose only*

Series	LM
Termination type	Female USB
IP rating	68
AWG wire size	0.00 - 0.00
Cable Ø	11.35 - 22.70 mm
Status	active

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model	EG*: Fixed receptacle, nut fixing
Keying	5 keys (alpha=95, beta=115, gamma=35, delta=25, plug: male contacts, receptacle: female contacts)
Housing Material	Aluminium (nickel plated [SAE AMS QQ N 290], anthracite color) shell and nut, other pieces bronze/brass
Weight	15.63 g

### Performance

Configuration	LM.U2A : USB
Insulator	
Rated Current	


### Others

Temp (min / max): -20°C / +200°C  
Humidity (max): 21 days at 95%  
Gunfire vibration: 25 Hz - 2000 Hz, 3 axis (Apache helicopter)

*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*

Vibration-Sine: 30 g, 3 axes, 12 hr [10 Hz - 2000 Hz]  
Vibration-Random: 37.8 g rms - 3 axes, 4 hr amb [50 Hz - 2000 Hz]  
Shock Resistance: 300 g [ 3 ms]  
Lighting strike EIA 364-75: 10K amps - 6 times  
Thermal shock: 5 cycles: -65°C to +150°C  
EMI Shielding EIA 364-66A: >= 80 dB (1 GHz), >=70 dB (3 GHz), >= 58 dB (6 GHz), >= 40 dB (10 GHz)  
Salt Spray Corrosion: max. 48 hr

# DRAWINGS

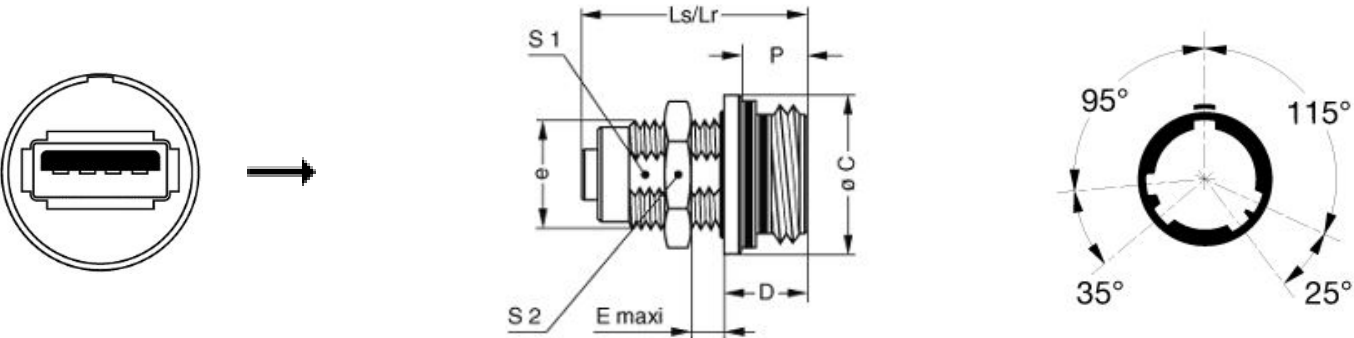

## Dimensions

	C	D	E	Ls	Ls	P	S1	S2	e
mm.	28	9.4	4	20	21.9	7.9	22.5	30	M24x1.0
in.	1,10	0,37	0,16	0,79	0,86	0,31	0,89	1,18	

# RECOMMENDED BY LEMO

## Tools

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[EGW.LM.U2A.XPL](#)