

## SUMMARY

### # Wires

Low voltage	1
-------------	---



*Image is for illustrative purpose only*

Series	00
Termination type	Male solder
IP rating	50
AWG wire size	28.00 - 20.00
Cable Ø	2.30 - 2.70 mm
Status	active
Matching parts	<a href="#">ERA.00.113.CTL</a>

### Download

[Request a quote](#)[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model	FFA*: Straight plug with cable collet and nut for fitting a bend relief
Keying	Circular, male
Housing Material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Variant	Z : Nut for fitting a bend relief
Weight	3.72 g

### Performance

Configuration	00.113 : 1 Low Voltage
Insulator	T: PTFE
Rated Current	8 Amps

### Specifications


Contact Type: Solder  
Vtest: 850 V (AC), 1200 V (DC)

### Others

Salt Spray Corrosion: >1000 hr

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# DRAWINGS

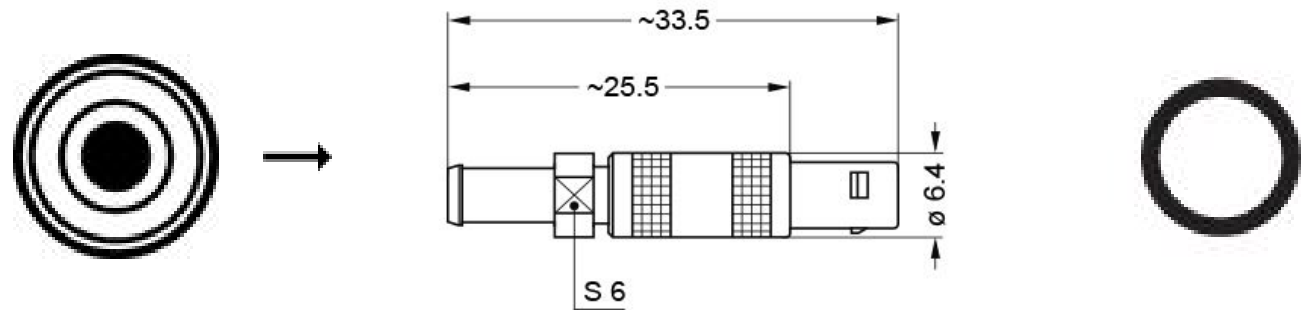

## Dimensions

	A	L	M
mm.	6.4	33.5	25.5
in.	0,25	1,32	1,00

# RECOMMENDED BY LEMO

## Tools

Spanner wrench: [DCD.00.003.PA060](#)

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[FFA.00.113.CTAC27Z](#)