

## SUMMARY

### # Wires

Low voltage 1



*Image is for illustrative purpose only*

Series 00  
Termination type Male solder  
IP rating 50  
AWG wire size 28.00 - 20.00  
Cable Ø 2.80 - 3.10 mm  
Status active  
Matching parts [ERA.00.113.CTL](#)

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model FFA\*: Straight plug with cable collet and nut for fitting a bend relief  
Keying Circular, male  
Housing Material Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces  
Variant Z : Nut for fitting a bend relief  
Weight 3.69 g

### Performance

Configuration 00.113 : 1 Low Voltage  
Insulator T: PTFE  
Rated Current 8 Amps

### Specifications


Contact Type: Solder  
Vtest: 850 V (AC), 1200 V (DC)

### Others

Salt Spray Corrosion: >1000 hr

*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*

# DRAWINGS

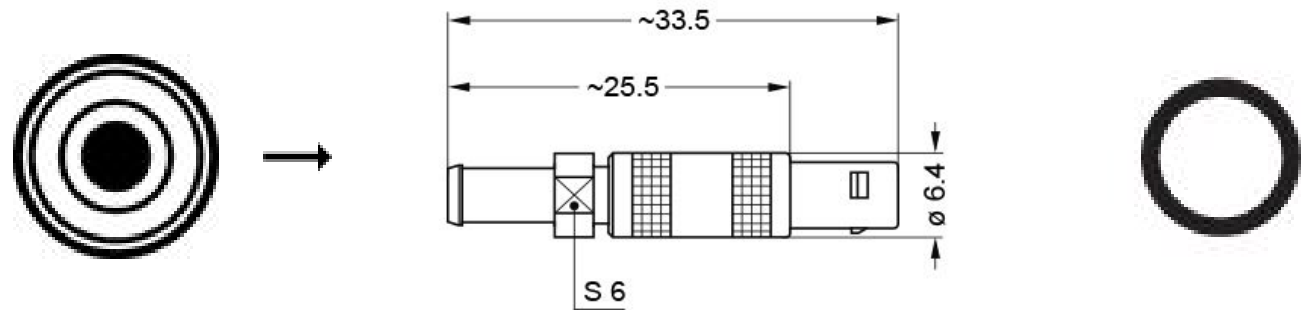

## Dimensions

	A	L	M
mm.	6.4	33.5	25.5
in.	0,25	1,32	1,00

# RECOMMENDED BY LEMO

## Tools

Spanner wrench: [DCD.00.003.PA060](#)

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[FFA.00.113.CTAC31Z](#)