

## SUMMARY

### # Wires

Low voltage 1



*Image is for illustrative purpose only*

Series 00  
Termination type Male crimp  
IP rating 50  
AWG wire size 32.00 - 28.00  
Cable Ø 0.00 - 0.00 mm  
Status active  
Matching parts [EGG.00.654.ZZM](#)

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model FG\*: Male crimp contact, standard barrel  
Keying No keying  
Housing Material Gold plated [ISO 27874] brass  
Weight .04 g


### Performance

Configuration  
Insulator  
Rated Current

### Others

12NC part number: 4022.438.73275

# DRAWINGS

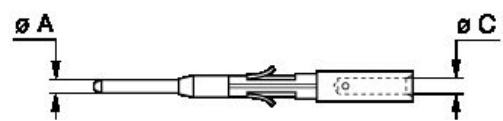

No keying

## Dimensions

	A	C
mm.	0.5	0.45
in.	0,02	0,02

# RECOMMENDED BY LEMO

## Tools

- Crimp Tool: [DPC.91.701.V](#)
- Positionner: [DCE.91.050.0VC](#)

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LEMO:](#)

[FGG.00.554.ZZC](#)