

SUMMARY

Wires

Low voltage 17



Image is for illustrative purpose only

Series	0R
Termination type	Male crimp
IP rating	50
AWG wire size	26.00 - 22.00
Cable Ø	1.60 - 6.20 mm
Status	active
Matching parts	EGG.0R.317.GLM

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	FGG*: Straight plug, key (G) or key (A), with cable collet
Keying	3 keys (alpha=50,beta=30, plug: male contacts, receptacle: female contacts)
Housing Material	Crastin® PBT (Polybutylene terephthalate), gray
Weight	13.92 g

Performance

Configuration	0R.317 : 17 low voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated Current	2.0 Amps


Specifications

Contact Type: Crimp
Test voltage (kV rms) Contact-contact: 1.35

Others

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

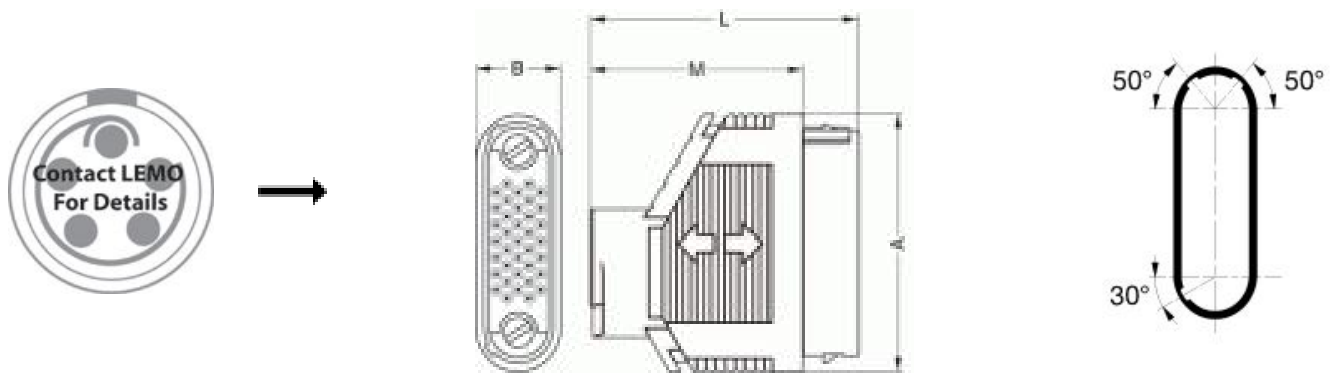

RECOMMENDED BY LEMO

Tools

Crimp Tool:	DPC.91.701.V
Crimp settings:	AWG/Selector = 22-24-26/6-5-5
Positionner:	DCE.91.070.BVC
Replacement contact:	FGG.0B.555.ZZC

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[FGG.0R.317.GLC62](#)