

SUMMARY

Wires



Image is for illustrative purpose only

Series	MH
Termination type	No contacts / Accessory
IP rating	68
AWG wire size	0.00 - 0.00
Cable Ø	6.60 - 7.50 mm
Status	active

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	FHE*: Straight plug (IP68)
Keying	Hermaphroditic keying (half moon insert) with male pin 1
Housing Material	Aluminium (nickel plated [SAE AMS QQ N 290], anthracite color) shell and nut, other pieces bronze/brass
Weight	55.67 g

Performance

Configuration	MH.03E : 6 FO TYPE F7
Insulator	
Rated Current	

Specifications


Contact LEMO for performance details.

Others

Salt Spray Corrosion: max. 48 hr

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

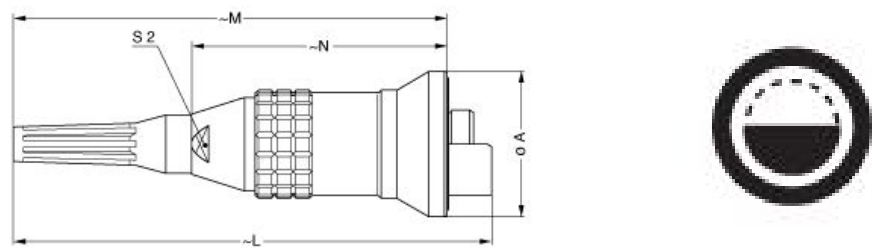

Dimensions

	A	L	M	N	S2
mm.	34	109.3	98.9	56.9	15
in.	1,34	4,30	3,89	2,24	0,59

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[FHE.MH.03E.XLZT76G](#)