

SUMMARY

Wires

Fiber optic	2
-------------	---

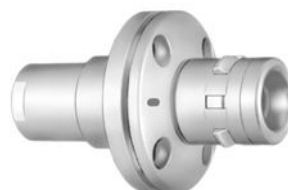


Image is for illustrative purpose only

Series	3K
Termination type	No contacts / Accessory
IP rating	68
AWG wire size	0.00 - 0.00
Cable Ø	0.00 - 0.00 mm
Status	active

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	FX*: Fixed plug with round flange and screw fixing
Keying	5 keys (alpha=95, beta=115, gamma=35, delta=25, plug: male contacts, receptacle: female contacts)
Housing Material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Weight	121.34 g

Performance

Configuration	3K.03A : 2 FO Type F2 ($\leq 140 \mu\text{m}$)
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated Current	

Specifications

Contact LEMO for performance details.


Others

Endurance (Shell):	5000 mating cycles
Temp (min / max):	-55°C / +200°C
Humidity (max):	$\leq 95\%$ [at 60 deg C / 140 F]

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Vibration: 15 g [10 Hz - 2000 Hz]
Shock Resistance: 100 g [6 ms]
Climatical Category: 50/175/21
Shielding (min): 95 dB (10 MHz)
Shielding (min): 80 dB (1 GHz)
Salt Spray Corrosion: >1000 hr

DRAWINGS

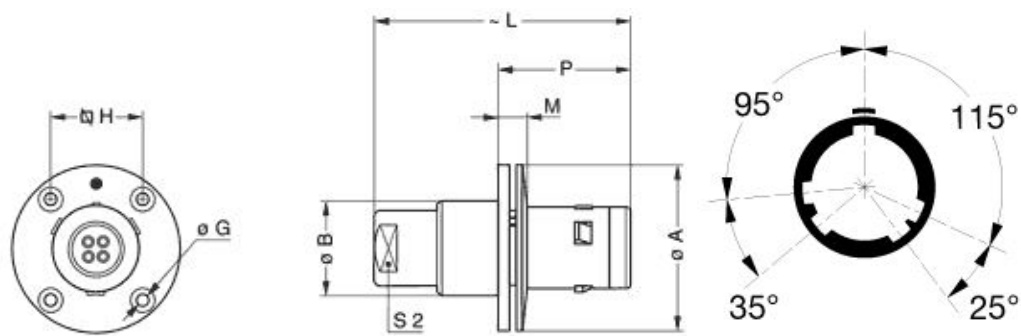

Dimensions

	A	B	G	H	L	M	P	S2
mm.	38	22.5	3.4	20.6	61	10	30	15
in.	1,50	0,89	0,13	0,81	2,40	0,39	1,18	0,59

RECOMMENDED BY LEMO

Tools

Spanner wrench: [DCD.3E.030.PA150](#)

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[FXR.3K.03A.CLZ](#)