

## SUMMARY

### # Wires



*Image is for illustrative purpose only*

Series	1B
Termination type	No contacts / Accessory
IP rating	0
AWG wire size	0.00 - 0.00
Cable Ø	2.50 - 2.90 mm
Status	active

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model	GMA*: Bend relief Yellow
Keying	No keying
Housing Material	Thermoplastic polyurethane elastomer (Elastollan 1185 A)
Variant	J : Yellow
Weight	.98 g

### Performance


Configuration	
Insulator	J: PEEK/PEEK
Rated Current	

### Others

Temp (min / max): -40°C / +80°C

*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*

# DRAWINGS

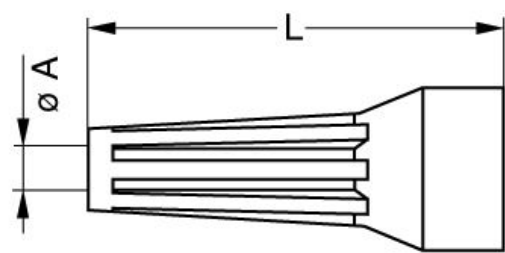

No keying

## Dimensions

	A	L
mm.	2.5	30
in.	0,10	1,18

# RECOMMENDED BY LEMO

## Tools

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[GMA.1B.025.DJ](#)