

## SUMMARY

### # Wires



*Image is for illustrative purpose only*

Series	1B
Termination type	No contacts / Accessory
IP rating	0
AWG wire size	0.00 - 0.00
Cable Ø	6.30 - 7.00 mm
Status	active

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model	GMA*: Bend relief Blue
Keying	No keying
Housing Material	Silicone elastomer VMQ
Variant	A : Blue
Weight	1.26 g

### Performance

Configuration
Insulator
Rated Current


### Others

Temp (min / max): -60°C / +200°C  
Temperature range in water steam: +140°C

*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*

---

# DRAWINGS

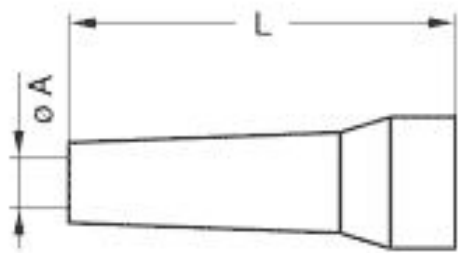

No keying

## Dimensions

	A	L
mm.	6.3	34
in.	0,25	1,34

---

# RECOMMENDED BY LEMO

## Tools

*LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[GMA.1B.063.RA](#)