

## SUMMARY

### # Wires



*Image is for illustrative purpose only*

|                  |                         |
|------------------|-------------------------|
| Series           | 00                      |
| Termination type | No contacts / Accessory |
| IP rating        | 0                       |
| AWG wire size    | 0.00 - 0.00             |
| Cable Ø          | 0.00 - 0.00 mm          |
| Status           | active                  |

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

|                   |  |
|-------------------|--|
| Shell Style/Model | GMB*: Bend relief Grey                                   |
| Keying            | No keying  |
| Housing Material  | Thermoplastic polyurethane elastomer (Elastollan 1185 A) |
| Variant           | G : Gray   |
| Weight            | .47 g  |

### Performance


|               |
|---------------|
| Configuration |
| Insulator     |
| Rated Current |

### Others

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

---

## DRAWINGS

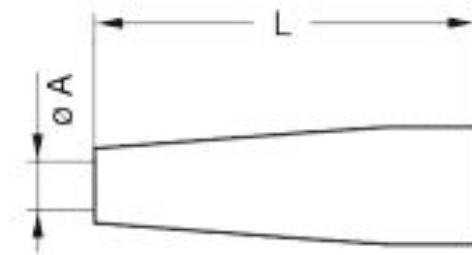

**No keying**

---

## RECOMMENDED BY LEMO

Tools

*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[GMB.00.018.DG](#)