

## SUMMARY

### # Wires

Low	10
High	0
Coax	0
Triax	0
Quad	0
Fiber	0
Fluidic	0



### Download

[Request a quote](#)

[Catalog](#)

### Series

Termination type	Female solder
IP rating	50
Cable Ø	0.00 - 0.00 mm
Matching parts	xxx

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model	XL_.XP*: Fixed socket, key (N) or keys (P, S and T),grey, with nut
Keying	3 key (alpha=30, plug: male contacts, receptacle: female contacts)
Housing Material	
Cable Fixing	∅ 0 - 0 mm
Variant	G : Gray front nut

### Performance


Configuration	M10 : 10 Low Voltage
Insulator	L: PEEK
Rated Current	

### Others

F ret (average): 130 N
Working temperature: -50 deg C to + 170 deg C
IP Rating: 50

# DRAWINGS

## Draws

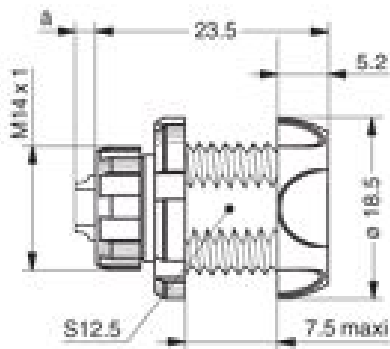

## Dimensions

	A	L	N	e
mm.	18.5	25.7	23.5	M14x1
in.	0.73	1.01	0.93	

# RECOMMENDED BY LEMO

## Tools

None

## Cables

CMN.10.T22.068QGC			
-------------------	--	--	--

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[XLN.M10.GLLG](#)