

SUMMARY

Wires

Low	0
High	0
Coax	0
Triax	0
Quad	0
Fiber	0
Fluidic	0



Image is for illustrative purpose only

Download

[Request a quote](#)

[Catalog](#)

Series	SP
Termination type	
IP rating	50
Cable Ø	5.30 - 6.50 mm
Matching parts	SRN.M13.BLL.6B
Status	active
Alternative part	

TECHNICAL DETAILS

Mechanics

Shell Style/Model	SA*: Straight plug, key (N) or keys (P, S and T), with white cable collet
Keying	3 keys (alpha=0, gamma=30, plug: male contacts, receptacle: female contacts)
Housing Material	Proprietary sulfone, white
Cable Fixing	∅ 5.3 - 6.5 mm
Variant	B : White collet nut
Weight	6.66 g

Performance

Configuration	
Insulator	
Rated Current	4.0 Amps

Specifications

Test voltage (kV rms) Contact-contact:	1.05
Air clearance min. (mm) or Creepage distance min. (mm):	0.50


LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Others

IP Rating: 50

DRAWINGS

Draws

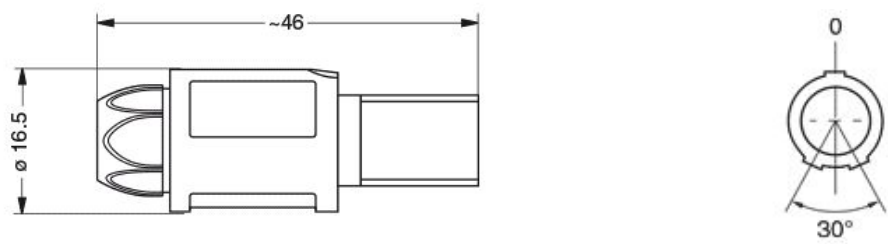

Dimensions

	A	L
mm.	16.5	46
in.	0,65	1,81

RECOMMENDED BY LEMO

Tools

Crimp Tool: DPC.91.701.V

Cables

130 222			
---------	--	--	--

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[SAN.M13.BLA.6B](#)