

## SUMMARY

### # Wires

Low voltage 2



*Image is for illustrative purpose only*

Series 1P  
Termination type Male solder  
IP rating 50  
AWG wire size 0.00 - 20.00  
Cable Ø 4.00 - 5.20 mm  
Status active  
Matching parts [PLG.M0.2GL.LR](#)

### Download

[Request a quote](#)

[Eplan](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model PA\*: Straight plug with cable collet  
Keying 1 key (alpha=0; Plug: male contact; Receptacle: female contact)  
Housing Material PSU (Polysulfone), gray  
Variant R : Red collet nut  
Weight 4.92 g

### Performance

Configuration 1P.M02 : 2 Low Voltage  
Insulator L: PEEK (UL 94 / V-0/1.5)  
Rated Current 10 Amps

### Specifications

Contact Type: Solder  
Contact Dia.: 1.3 mm (0.0512in)  
Bucket Dia.: 1.1 mm (0.04in)  
Max. Solid Conductor: 0.5 mm<sup>2</sup> (AWG 20)  
Max. Stranded Conductor: 0.5 mm<sup>2</sup> (AWG 20)  
R (max): 3.5 mOhm  
Test voltage (kV rms) Contact-contact: 1.2


*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*

Air clearance min.: 1.3 mm  
Creepage distance min.: 1.3 mm

Others

Endurance (Shell): >2000 mating cycles  
Temp (min / max): -50°C / +150°C  
F ret (min): 50 N  
F ret (max): 150 N  
Steam sterilization: > 100 times (with potting on rear connection)



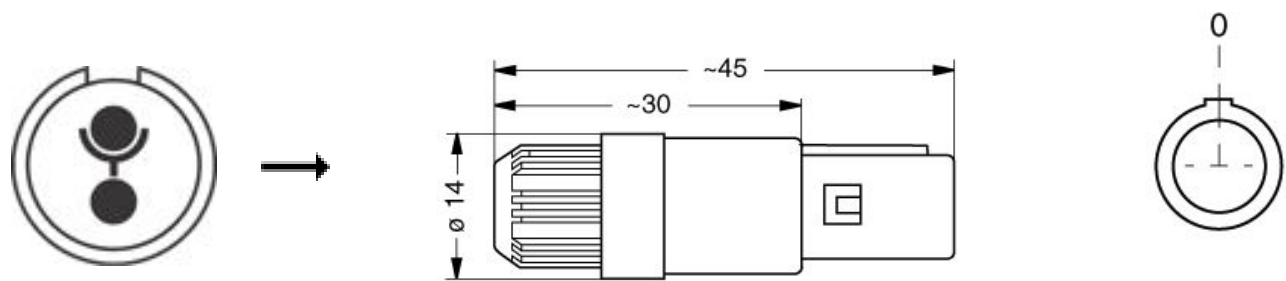




DRAWINGS







RECOMMENDED BY LEMO

Tools

Cables

|                    |               |       |   |
|--------------------|---------------|-------|---|
| CMN.02.T20.047PGZE |               | Grey  |  |
| CMN.02.T20.047PNZE |               |       |  |
| CMN.02.T20.048QGZE | TPR (medical) | Grey  |  |
| 120240             | PVC           | Black |  |
| 120250             | PVC           | Grey  |  |
| 120501             | PVC           | Grey  |  |
|                    |               |       |  |

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

|       |     |        |   |
|-------|-----|--------|---|
| 20260 | PVC | Black  |   |
| 20264 | PVC | Black  |   |
| 20266 | PVC | Violet |   |
| 2221  | PVC | Black  |  |
| 2280  | PVC | Black  |  |
| 4082  | PVC | Grey   |   |

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LEMO:](#)

[PAG.M0.2GL.AC52R](#)