

## SUMMARY

### # Wires

Low voltage 17



*Image is for illustrative purpose only*

Series	0R
Termination type	Female crimp
IP rating	50
AWG wire size	26.00 - 22.00
Cable Ø	1.60 - 6.20 mm
Status	active
Matching parts	<a href="#">FGG.0R.317.GLC62</a>

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model	PHG*: Free receptacle, cable collet key (G) or key (A), with cable collet
Keying	3 keys (alpha=50,beta=30, plug: male contacts, receptacle: female contacts)
Housing Material	Crastin® PBT (Polybutylene terephthalate), gray
Weight	8.84 g

### Performance

Configuration	0R.317 : 17 low voltage
Insulator	L: PEEK (UL 94 / V-0/1.5)
Rated Current	2.0 Amps


### Specifications

Test voltage (kV rms) Contact-contact: 1.35

### Others

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# DRAWINGS

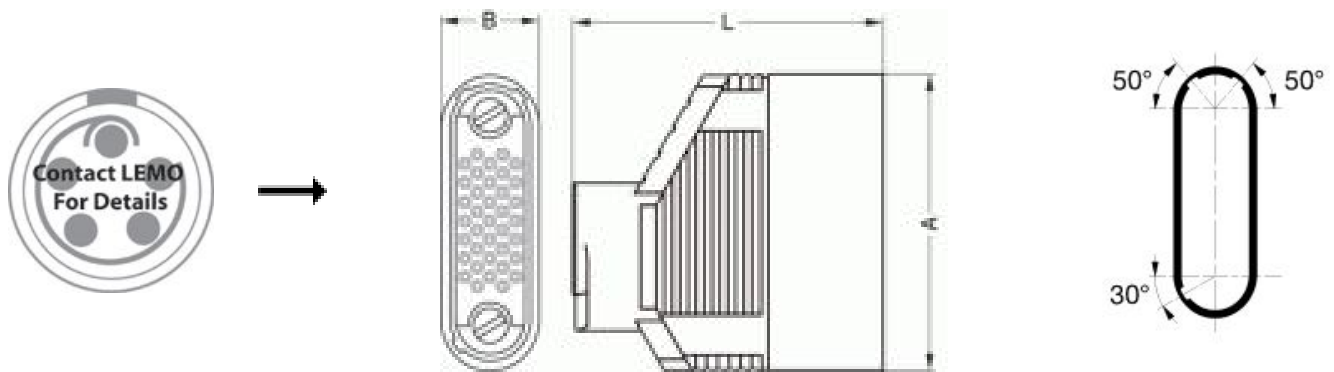

---

## RECOMMENDED BY LEMO

### Tools

Crimp Tool:	<a href="#">DPC.91.701.V</a>
Crimp settings:	AWG/Selector = 22-24-26/6-5-5
Positionner:	<a href="#">DCE.91.070.BVM</a>
Replacement contact:	EGG.0B.655.ZZM

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LEMO:](#)

[PHG.0R.317.GLM62](#)