

SUMMARY

Wires

Fiber optic	1
-------------	---



Image is for illustrative purpose only

Series	00
Termination type	Fibre optic contact
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	0.00 - 0.00 mm
Status	active
Matching parts	FGG.00.BB4.CCBE30S

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	PK*: Fixed receptacle, nut fixing, with bend relief included
Keying	1 key (alpha=0, plug: male contacts, receptacle: female contacts)
Housing Material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Weight	10.39 g

Performance

Configuration	FO/BB4 : 1 FO 126 um hole
Insulator	C: Zirconia Ceramic
Rated Current	

Specifications


Contact Type: F4 (included)
Ferrule Material: Zirconia Ceramic
Hole dia.(um): 126
Core/Cladding (um): 50/125

Others

Salt Spray Corrosion: >1000 hr

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

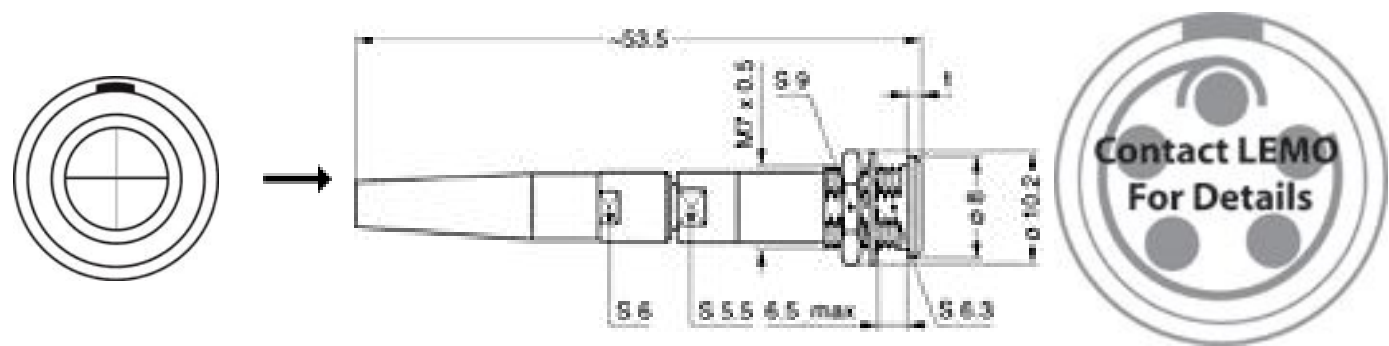

Dimensions

	A	B	E	L	M	S1	S2	S3	e
mm.	10	12.4	7	35.5	1.2	8.2	7	11	M9x0.6
in.	0,39	0,49	0,28	1,40	0,05	0,32	0,28	0,43	

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[PKG.00.BB4.CCSE30S](#)