

SUMMARY

Wires

Coax	1
------	---



Image is for illustrative purpose only

Series	01
Termination type	Female solder
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	0.00 - 0.00 mm
Status	active
Matching parts	FFS.01.250.DLAE24

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model	PSS.01*: Fixed receptacle, nut fixing, for cable crimping
Keying	Circular, female
Housing Material	Brass (gold plated [ISO 27874]) shell, collet nut, brass latch sleeve and mid pieces
Weight	1.84 g

Performance


Configuration	01.250 : 1 Coax (50 Ohm)
Insulator	
Rated Current	

Others

Endurance (Shell): 1000 mating cycles

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

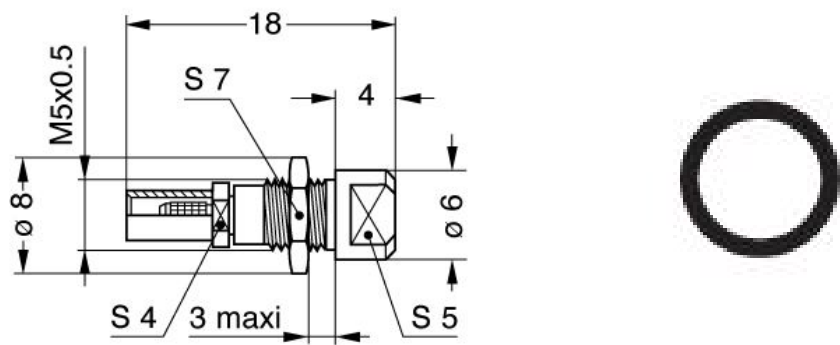

Dimensions

	A	B	E _{max}	L	M	S1	S2	S3	e1
mm.	6	8	3	18	4	7	4	5	M5x0.5
in.	0,24	0,31	0,12	0,71	0,16	0,28	0,16	0,20	

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[LEMO:](#)

[PSS.01.250.DLLE24](#)