

## SUMMARY

### # Wires

Low voltage 1



*Image is for illustrative purpose only*

|                  |                |
|------------------|----------------|
| Series           | SP             |
| Termination type | Male crimp     |
| IP rating        | 50             |
| AWG wire size    | 26.00 - 22.00  |
| Cable Ø          | 0.00 - 0.00 mm |
| Status           | active         |

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

|                   |   |
|-------------------|---|
| Shell Style/Model | SAN*: Male crimp contact for REDEL SP series, standard barrel |
| Keying            | No keying   |
| Housing Material  | Gold plated [ISO 27874] brass                                 |
| Weight            | .13 g   |


### Performance

Configuration  
Insulator  
Rated Current

### Others

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# DRAWINGS

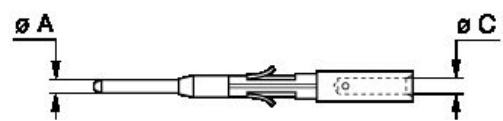

No keying

## Dimensions

|     | A    | C    |
|-----|------|------|
| mm. | 0.7  | 0.8  |
| in. | 0,03 | 0,03 |

# RECOMMENDED BY LEMO

## Tools

- Crimp Tool: [DPC.91.701.V](#)
- Positionner: [SOE.070.VC](#)

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[SAN.520.ZZC](#)