

SUMMARY

Wires

Low	0
High	0
Coax	1
Triax	0
Quad	0
Fiber	0
Fluidic	0



Image is for illustrative purpose only

Download

[Request a quote](#)

[Catalog](#)

Series	03
Termination type	Male solder
IP rating	68
Cable Ø	2.40 - 2.60 mm
Matching parts	HVP.03.250.CLLP
Status	active
Alternative part	

TECHNICAL DETAILS

Mechanics

Shell Style/Model	FVN*: Straight plug (coaxial) with cable collet and nut for fitting a bend relief
Keying	
Housing Material	Brass (chrome plated) shell and collet nut, nickel plated brass latch sleeve and mid pieces
Cable Fixing	C27: 2.4 - 2.6 mm
Variant	Z : Nut for fitting a bend relief
Weight	8.25 g

Performance

Configuration	03.250 : 1 Coax (50 Ohm)
Insulator	
Rated Current	

Specifications

Contact Type: Solder


Others

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Pressure: 60 bars (120 bars with LEMO cable assembly)
IP Rating: 68

DRAWINGS

Draws

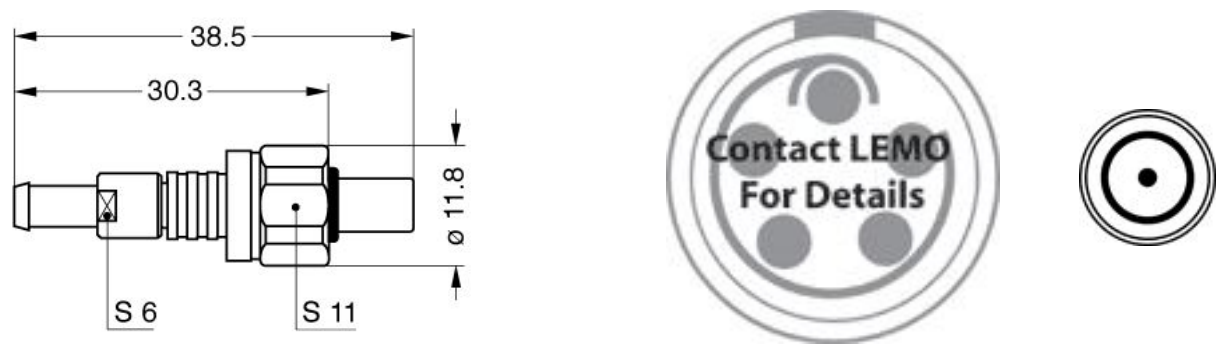

Dimensions

	A	L	M	S1	S2
mm.	11.8	38.5	30.3	11	6
in.	0,46	1,52	1,19	0,43	0,24

RECOMMENDED BY LEMO

Tools

None

Cables

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LEMO:

[FVN.03.250.CLAC27Z](#)